




## Data Sheet

### Control cabinet socket, DIN rail mounting

Item No. 2865670

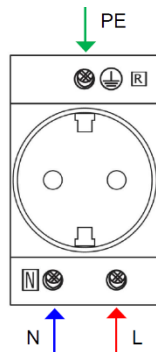

Item No. 2865671

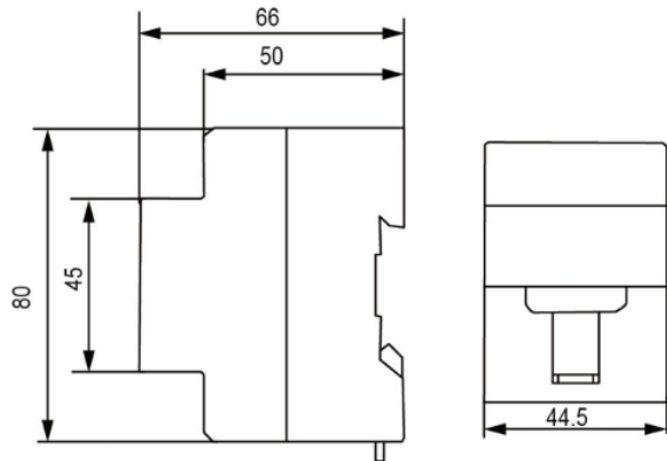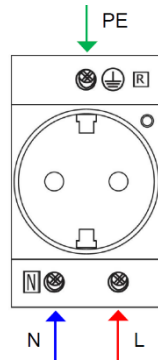

Item No.	2865670	2865671
Rated Voltage	250 V/AC	
Rated Current	16 A	
LED indication	No	Yes
Width	44.5 mm	
Frequency	50/60 Hz	
Rated Insulation voltage $U_i$	5000 V	
Connection cross section	1.5 - 4 mm <sup>2</sup>	
Electrical Life	5000 times	
Protection class	IP20	
Standard mounting	35 mm DIN rail	
Ambient temperature	-20 - 60°C	
Operating humidity	≤ 90%	
Enhanced protection against accidental contact	Yes	