



SETRON, cylindrical fuse holder, 10 x 38 mm, 1-pole, In: 30 A, Ue DC: 1000 V, for photovoltaic application

Model		
product brand name	SETRON	
product designation	Cylindrical fuse holder	
design of the product	For photovoltaic applications	
General technical data		
number of poles	1	
size of fuse link	10 x 38 mm	
Supply voltage		
operating voltage	1 000 V	
● at DC rated value		
protection class IP	IP20	
Mechanical Design		
height	85 mm	
width	18 mm	
depth	65 mm	
net weight	64 g	
Certificates		
reference code according to IEC 81346-2	F	
General Product Approval		Declaration of Con- formity



[Confirmation](#)



Declaration of Con- formity	other
--------------------------------	-------



[Miscellaneous](#)

[Confirmation](#)

[Miscellaneous](#)

Further information

Siemens has decided to exit the Russian market (see here).
<https://press.siemens.com/global/en/pressrelease/siemens-wind-down-russian-business>
Siemens is working on the renewal of the current EAC certificates.
Please contact your local Siemens office on the status of validity of the EAC certification if you intend to import or offer to supply these products to an EAC relevant market (other than the sanctioned EAEU member states Russia or Belarus).
Information on the packaging
<https://support.industry.siemens.com/cs/ww/en/view/109813875>

Information- and Downloadcenter (Catalogs, Brochures,...)

<http://www.siemens.com/lowvoltage/catalogs>

Industry Mall (Online ordering system)

<https://mall.industry.siemens.com/mall/en/en/Catalog/product?mlfb=3NW7013-4>

Service&Support (Manuals, Certificates, Characteristics, FAQs,...)

<https://support.industry.siemens.com/cs/ww/en/ps/3NW7013-4>

Image database (product images, 2D dimension drawings, 3D models, device circuit diagrams, ...)


http://www.automation.siemens.com/bilddb/cax_en.aspx?mlfb=3NW7013-4

CAX-Online-Generator

<http://www.siemens.com/cax>

Tender specifications

<http://www.siemens.com/specifications>

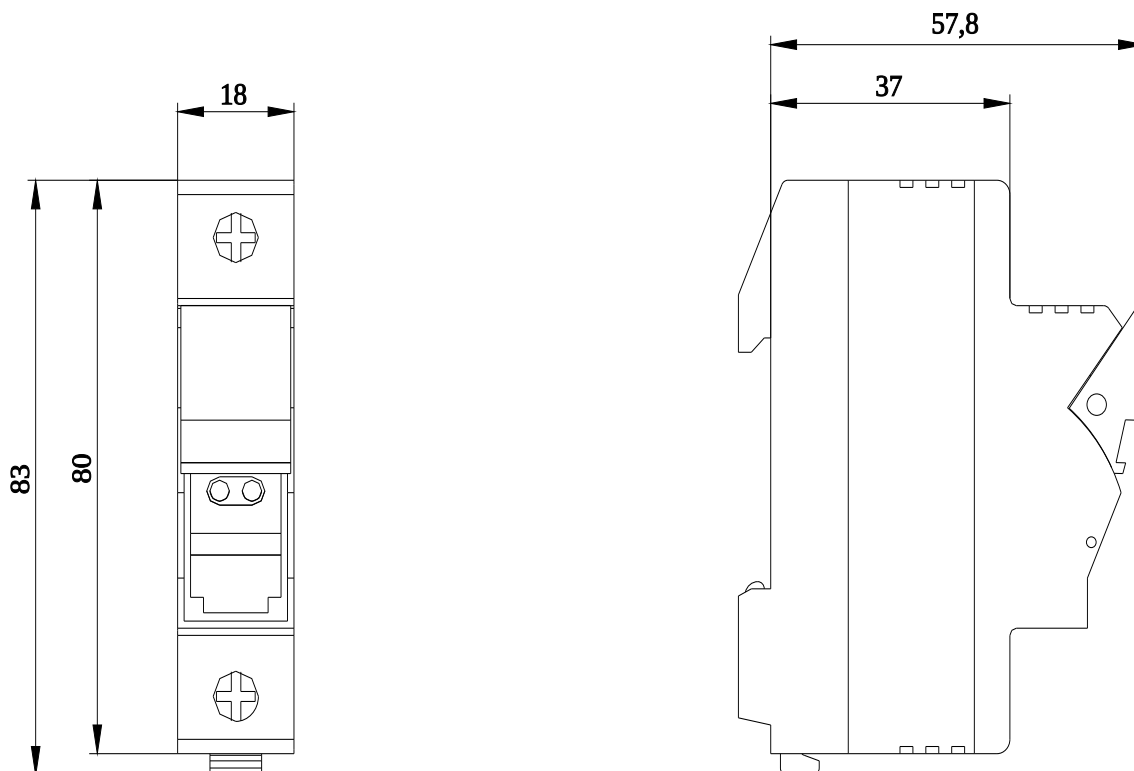

last modified:

7/9/2021 

