




**200pcs Insulated Wire-end-Ferrules assortment-  
mini kit set, 0.14mm<sup>2</sup> / 0.25mm<sup>2</sup> / 0.34mm<sup>2</sup> / 0.5mm<sup>2</sup>  
DE color code standard  
Typ.2010C392**



Insulator material: PVC  
Terminal material: Tinned Copper  
Working Temperature: 75°C max.  
Rating voltage: 600 V/AC max.

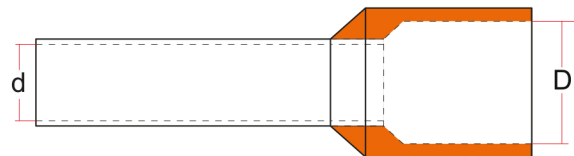

Wire range	Diameter Dø	Diameter dø	Colour	contents
0.14 mm <sup>2</sup>	1.6 mm	0.80 mm	Grey	50pcs
0.25 mm <sup>2</sup>	1.9 mm	0.80 mm	Light blue	50pcs
0.34 mm <sup>2</sup>	1.9 mm	0.80 mm	Turquoise blue	50pcs
0.5 mm <sup>2</sup>	2.6 mm	0.95 mm	Orange	50pcs