




**36pcs Insulated Twin cable Ferrules assortment-
mini kit set, 2.5mm² / 4.0mm² / 6.0mm² / 10mm²
DE color code standard
Typ.2010C395**



Insulator material: PVC
Terminal material: Tinned Copper
Working Temperature: 75°C max.
Rating voltage: 600 V/AC max.

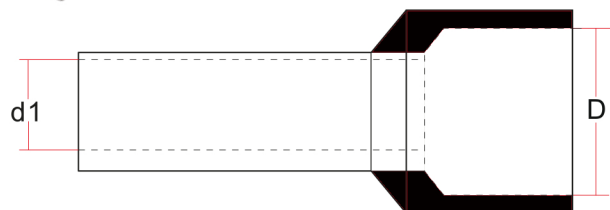

Wire range	Diameter Dø	Diameter dø	Colour	contents
2 x 2.5 mm ²	8.0 mm	2.9 mm	Blue	15pcs
2 x 4.0 mm ²	8.8 mm	3.8 mm	Grey	10pcs
2 x 6.0 mm ²	9.5 mm	4.9 mm	Black	7pcs
2 x 10 mm ²	12.6 mm	6.5 mm	Ivory	4pcs