



Standard Zip-Lock-Bag Polyethylene 100 pcs. set

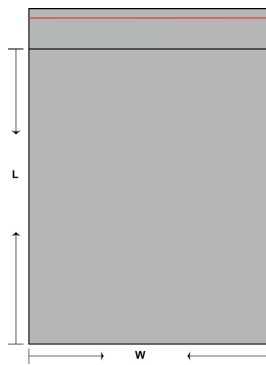

Zip-Lock-Bag clear

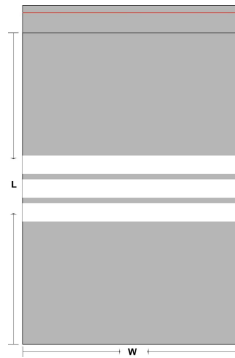

Zip-Lock-Bag with marking strips

Zip-Lock-Bags are indispensable products and are used for a wide range of applications! The zip mechanism at the bag opening (marked by a red line) allows the bags to be opened and closed absolutely quietly as well as wear-free. The standard material thickness of 0.05 mm is the optimum thickness for almost all applications and an all-rounder in terms of stability, transparency and flexibility. The plastic bags reliably protect small parts from external environmental influences, dirt and dust. The red line makes it easy to determine which side is open. The variants differ in size and a completely transparent/clear version or with three marking strips. **Keep out of reach of children!**

Technical data: Material: Polyethylene (PE) • Material thickness: 50 µm • Temperature-range: -40°C ... 60°C • Color: Transparent • Content: 100 pcs. per set.

Item-No.	Width (W)	Length (L)	Design	EAN/UPC Code	Content/Set
23SA054	40 mm	60 mm	without marking strips	4260732283317	100 pcs.
23SA055	60 mm	80 mm	without marking strips	4260732283324	100 pcs.
23SA056	80 mm	120 mm	without marking strips	4260732283331	100 pcs.
23SA057	80 mm	180 mm	without marking strips	4260732283348	100 pcs.
23SA058	100 mm	120 mm	without marking strips	4260732283355	100 pcs.
23SA059	100 mm	150 mm	without marking strips	4260732283362	100 pcs.
23SA060	100 mm	200 mm	without marking strips	4260732283379	100 pcs.
23SA061	120 mm	180 mm	without marking strips	4260732283386	100 pcs.
23SA062	150 mm	200 mm	without marking strips	4260732283393	100 pcs.
23SA063	180 mm	250 mm	without marking strips	4260732283409	100 pcs.
23SA064	220 mm	280 mm	without marking strips	4260732283416	100 pcs.
23SA065	40 mm	60 mm	with marking strips	4260732283423	100 pcs.
23SA066	60 mm	80 mm	with marking strips	4260732283430	100 pcs.
23SA067	80 mm	120 mm	with marking strips	4260732283447	100 pcs.
23SA068	80 mm	180 mm	with marking strips	4260732283454	100 pcs.
23SA069	100 mm	120 mm	with marking strips	4260732283461	100 pcs.
23SA070	100 mm	150 mm	with marking strips	4260732283478	100 pcs.
23SA071	100 mm	200 mm	with marking strips	4260732283485	100 pcs.
23SA072	120 mm	180 mm	with marking strips	4260732283492	100 pcs.
23SA073	150 mm	200 mm	with marking strips	4260732283508	100 pcs.
23SA074	180 mm	250 mm	with marking strips	4260732283515	100 pcs.
23SA075	220 mm	280 mm	with marking strips	4260732283522	100 pcs.