


SIVACON, Roof, with Ventilation openings with Ventilation openings IP40, W: 800 mm, T: 400 mm, zinc-plated

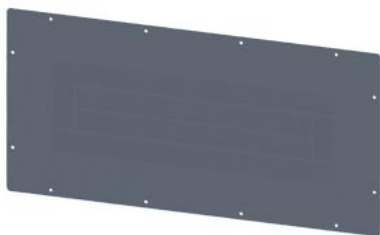

Model			
product brand name	SIVACON		
product designation	top plate		
design of the product	With ventilation openings		
design of the surface	galvanized		
design of the product EMC version	No		
Protection class			
protection class IP	IP40		
Suitability			
suitability for use for outside use	No		
Product details			
product component			
• cable entry			
• ventilation			
Mechanical Design			
width	800 mm		
depth	400 mm		
net weight	4.1 kg		
material	steel		
General Product Approval		Declaration of Conformity	Test Certificates

[Confirmation](#)



[Special Test Certificate](#)

other

[Miscellaneous](#)

[Confirmation](#)

[Miscellaneous](#)

Further information

Siemens has decided to exit the Russian market (see here).

<https://press.siemens.com/global/en/pressrelease/siemens-wind-down-russian-business>

Siemens is working on the renewal of the current EAC certificates.

Please contact your local Siemens office on the status of validity of the EAC certification if you intend to import or offer to supply these products to an EAC relevant market (other than the sanctioned EAEU member states Russia or Belarus).

Information on the packaging

<https://support.industry.siemens.com/cs/ww/en/view/109813875>

Information- and Downloadcenter (Catalogs, Brochures,...)

<http://www.siemens.com/lowvoltage/catalogs>

Industry Mall (Online ordering system)

<https://mall.industry.siemens.com/mall/en/en/Catalog/product?mlfb=8MF1084-2UD30-0A>

Service&Support (Manuals, Certificates, Characteristics, FAQs,...)

<https://support.industry.siemens.com/cs/ww/en/ps/8MF1084-2UD30-0A>

Image database (product images, 2D dimension drawings, 3D models, device circuit diagrams, ...)


http://www.automation.siemens.com/bilddb/cax_en.aspx?mlfb=8MF1084-2UD30-0A

CAX-Online-Generator

<http://www.siemens.com/cax>

Tender specifications

<http://www.siemens.com/specifications>

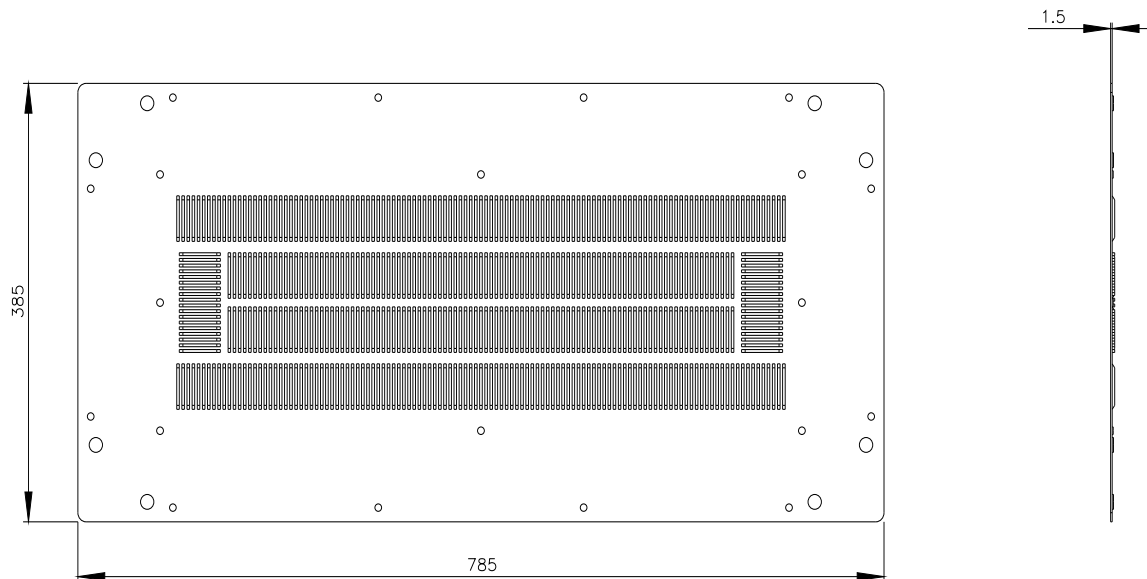

last modified:

5/6/2022 

