

# Tapo Smart IoT Hub with Chime



Tapo H100



Smart Alarm



Smart Doorbell



19 Ringtone  
Options




Up to 64  
Devices



## // Tapo Smart Ecosystem

Tapo is the easy way to turn your home into a smart home. At the center of it all is the Tapo Hub. With superior ultra-low-power performance, Tapo Hub connects wirelessly with a wide range of Tapo accessories. So you can easily control and monitor your home from anywhere.

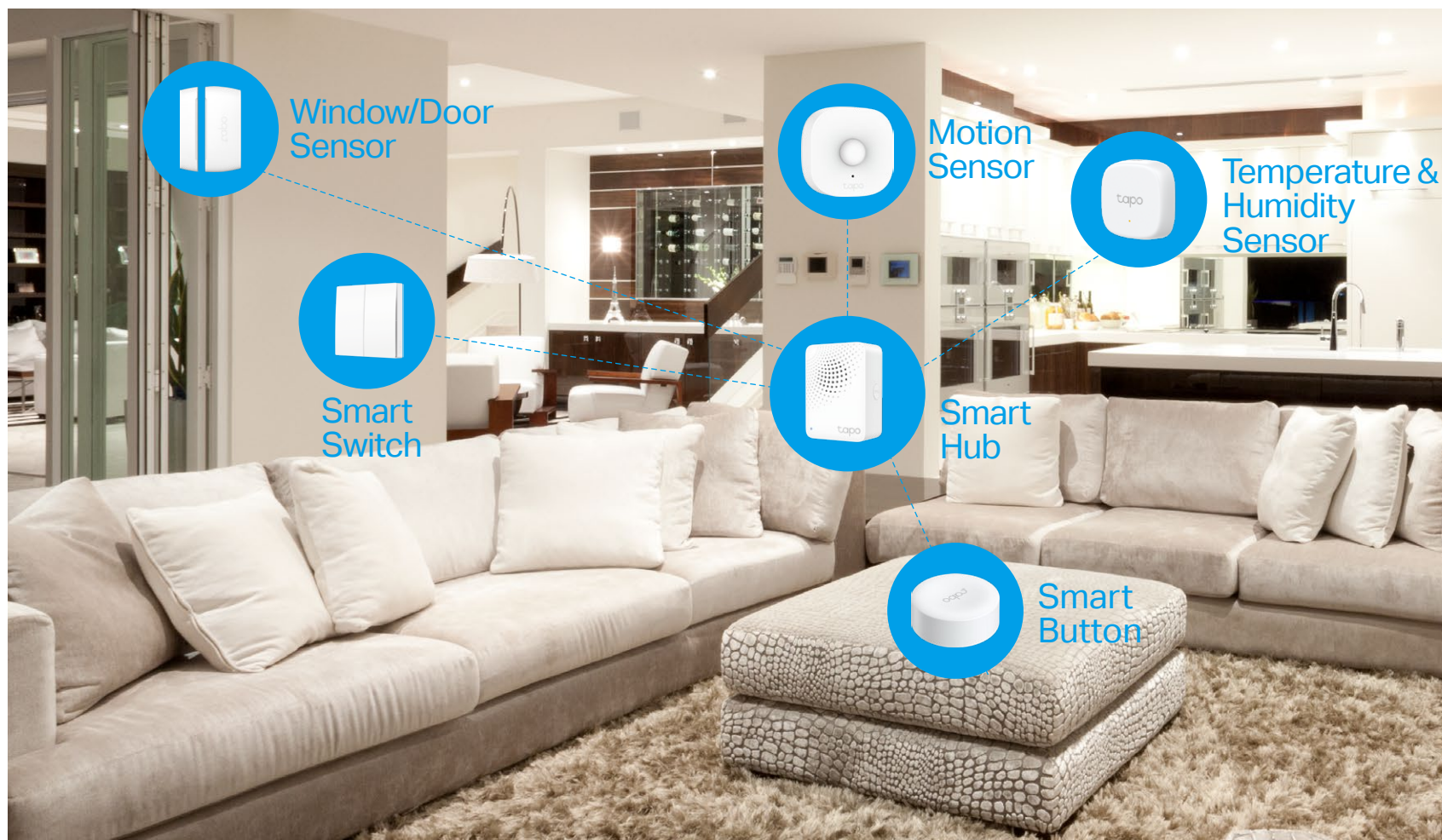

## // 3 in 1 Device for All Your Needs<sup>†</sup>



Tapo H100



### Smart IoT Hub

Use a long-distance, low-power wireless protocol to connect to battery-powered Tapo devices.



### Smart Alarm

Protect your home security by coordinating with Tapo smart sensors (motion sensor, window/door sensor, and more).



### Smart Doorbell

Easily build your smart doorbell system, by installing the Tapo smart button on the door.

<sup>†</sup>To build a smart alarm or smart doorbell, the Tapo Hub will need to work with certain smart devices.

## // Features

- **Ultra-Long Distance Connection** – With the low frequency wireless protocol, Tapo hub sends and receives data steadily throughout your home.
- **Ultra-Low-Power Performance** – Connect wirelessly with a wide range of Tapo accessories and never let your guard down.
- **Real-Time Notifications** – Monitor your entire home and all connected devices to get instant alerts when the activity is detected. The built-in alarm gives you more than enough protection.
- **19 Ringtone Options** – 90 DB<sup>†</sup> built-in multiple ringtones for your customized scenarios.
- **Up to 64 Devices<sup>#</sup>** – Connect multiple devices to create a smart ecosystem for your home.
- **Device Sharing** – Easily share management permissions with each member of your family.
- **Easy Setup and Use** – No wiring required. Set up quickly and manage easily through the free Tapo app.
- **Flame-Retardant<sup>△</sup>** - PC flame-retardant materials help minimize burning hazards.

<sup>†</sup>Decibel values may vary by ringtones and environmental factors.


<sup>#</sup>The max connections may vary by the types of smart devices connected.

<sup>△</sup>Made with V-0 (UL94) flame-retardant materials.

## // Specifications


### General

- Wireless: 2.4 GHz Wi-Fi, 868 MHz for connected devices<sup>§</sup>
- Rating: AC, 100-240 V, 50/60 Hz
- Power Consumption: 0.5 W
- Standby Power Consumption: 0.1 W
- Material: V-0 (UL-94) Flame retardant PC<sup>^</sup>
- LED&Button: Status LED, SYNC/Silence Button
- Built-in: 90 DB<sup>‡</sup> alarm, 19 ringtones

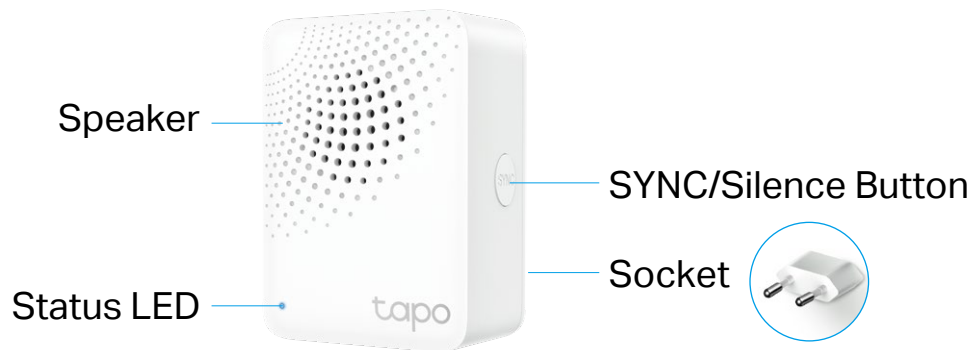

### Others

- Package Contents:  
Smart Hub Tapo H100  
Quick Start Guide
- Certifications: CE, RoHS
- Operating Temperature: 0 °C– 40 °C (32°F–104°F )
- Operating Humidity: 10%–90%RH, Non-condensing
- Dimensions: 72×70.3×51 mm (2.8×2.7×2 inch)

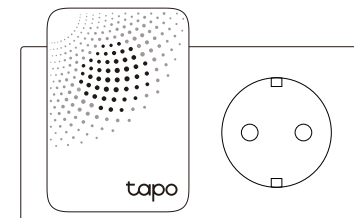

<sup>§</sup>The specific working frequencies are 863 MHz to 865 MHz, and 868 MHz to 868.6 MHz.

<sup>^</sup>Made with V-0 (UL94) flame-retardant materials.

<sup>‡</sup>Decibel values may vary by ringtones and environmental factors.

Please do not use in damp environments or outdoors. For more information, please visit <https://www.tapo.com/>

Specifications are subject to change without notice. All brands and product names are trademarks or registered trademarks of their respective holders.

©2022 TP-Link