

Item no.: 2886740

Data Sheet

Shaft coupling 28 x 78 mm - 12 mm shaft, Outer diameter : 55 mm



Technical data

Bore Ø: 28.0 mm, 12.0 mm

Dim(Ø x L): 55 mm x 78 mm

(Ø): 55 mm

Length: 78 mm

Rated Torque (TKN) : 60 N.m.

Max. Torque (TK Max.) : 120 N.m.


Screw type : M6

Material: Aluminum alloy, Polyurethane

Product type: Backlash free elastomer coupling

Item no.: 2886740

Data Sheet

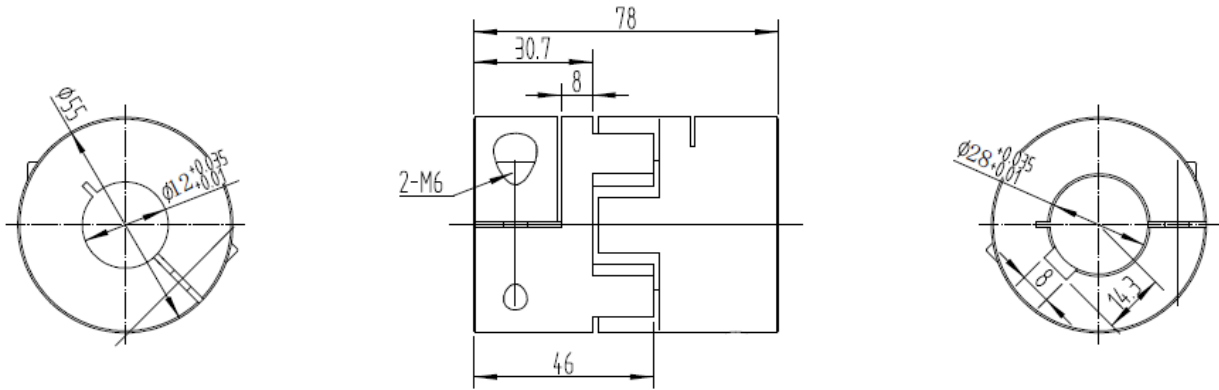

Abmessungen in mm