


## Data Sheet

### Ceramic Electric PTC heating

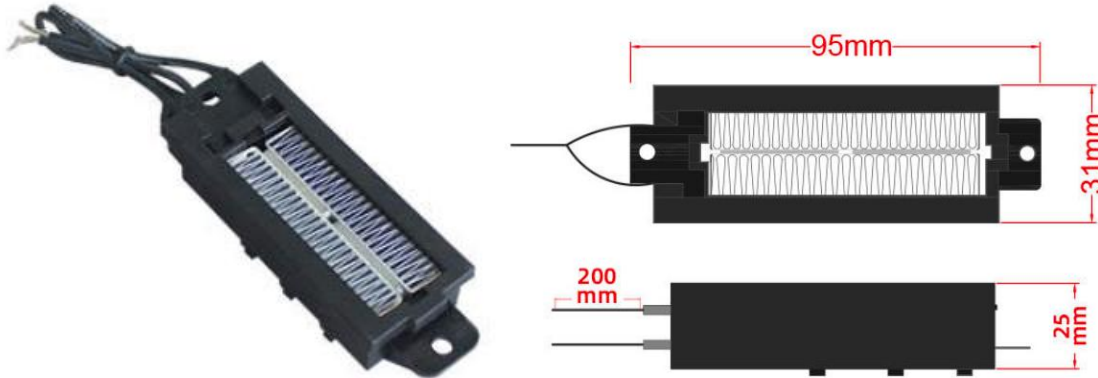

Item No.	2887003	2887004
Rated Voltage	12 V AC/DC	24 V AC/DC
Rated Power	50 W	70 W
Inrush Power	≤ 100 W	≤ 250 W
Withstand voltage	20 V	40 V
Rated current	4 A	3 A
Impulse current	8 A	10 A
Chip temperature	TS260	
Dimensions (mm)	95 x 31 x 25	
Mounting Hole Dimension (mm)	4.5 mm	
PTC wire / Fan wire material	Silica gel	
Wire length (mm)	200	
Resistance wire temperature	> 200°C	
Heating material	PTC	
Bracket material	PA66	
Heat shrinkable tube sleeve temperature resistance	> 300°C	
Heater life	> 50000 h	