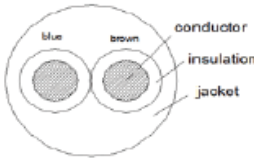


Data Sheet

Cable specification				
STYLE		H07RN-F 2*2.5		
Standard		EN50525		
Applications		Heavy outdoor wire		
Construction Details:				
Test Item		Unit	2*2.5	
Conductor	Material		Copper	
	Construction		49/0.238±0.005	
	Conductor DC resistance at 20℃ ≤		20℃ ≤7.98Ω/km	
Core Insulation	Material		EPDM	
	Avg. thickness	mm	0.9	
	Min. thickness	mm	0.71	
	Over Diameter	mm	3.85±0.10	
	Surface		Smooth	
	Colors		brown、blue	
lay	filler		NO	
Jacket	Material		CPE	
	Avg. thickness	mm	1.7	
	Min. thickness	mm	1.35	
	Over Diameter	mm	10.9±0.4	
	Surface		Smooth	
	Colors		BLACK	
Marking			≪VDE ≫ 40015999 H07RN-F 450/750V 2×2.5mm ² RIFENG	