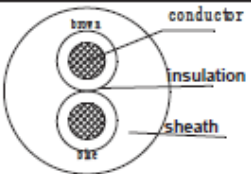


Item no.: 2898732

# Data Sheet

SPECIFICATION			
Style	H07RN-F 2x4		
Standard	EN50525-2-21		
Applications	Heavy duty rubber cable		
Construction Details:			
Test Item	Unit	2x4	
Conductor	Material	Bare Copper	
	Construction $\leq$	56/0.284 $\pm$ 0.01	
	Conductor DC resistance at 20°C $\leq$	$\Omega$ /km	4.95
Core Insulation	Material	EPDM	
	Avg. thickness	mm	1.0
	Min. thickness	mm	0.8
	Surface	Smooth	
	Colors	brown, blue	
Jacket	Material	CPE	
	Avg. thickness	mm	1.8
	Min. thickness	mm	1.43
	Over Diameter	mm	12.9 $\pm$ 0.6
	Surface	Smooth	
	Colors	BLACK	
marking	$\langle$ VDE $\rangle$ 40015999 H07RN-F 450/750V 2x4mm <sup>2</sup> RIFENG		