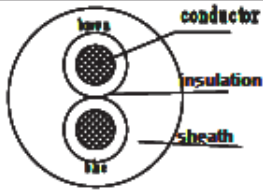


Item no.: 2898733

# Data Sheet

SPECIFICATION			
Style		H07RN-F	
Standard		EN50525	
Applications		Heavy duty rubber cable	
			
Construction Details:			
Test Item		Unit	2x6
Conductor	Material		Bare Copper
	Construction	mm	84/0.284±0.01
	Conductor DC resistance at 20°C ≦	Ω/km	3.3000
Core Insulation	Material		EPDM
	Avg. thickness	mm	1
	Min. thickness	mm	0.8
	Colors		brown、blue
Jacket	Material		CPE
	Avg. thickness	mm	2
	Min. thickness	mm	1.60
	Over Diameter	mm	14.6±0.6
	Surface		Smooth
	Colors		BLACK
marking	<VDE> 40015999 H07RN-F 450/750V 2x6mm² RIFENG		