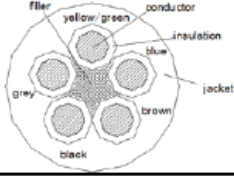


Item no.: 2898737

# Data Sheet

Cable specification		
STYLE	H07RN-F 5G1.5	
Standard	EN50525	
Applications	Heavy outdoor wire	
		
Construction Details:		
Test Item	Unit	5G1.5
Conductor	Material	Copper
	Construction	30/0.237±0.005
	Conductor DC resistance at 20°C ≤	20°C ≤ 13.3Ω/km
Core Insulation	Material	EPDM
	Avg. thickness	mm 0.8
	Min. thickness	mm 0.62
	Over Diameter	mm 3.15±0.10
	Surface	Smooth
	Colors	Yellow/green, blue, brown, black, grey
lay	filler	Cotton yarn
Jacket	Material	CPE
	Avg. thickness	mm 1.8
	Min. thickness	mm 1.43
	Over Diameter	mm 12.2±0.40
	Surface	Smooth
	Colors	BLACK
Marking	◁ VDE ▷ 40015999 H07RN-F 450/750V 5G1.5mm <sup>2</sup> RIFENG	