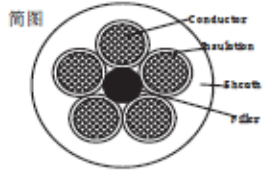


Item no.: 2898739

Data Sheet

SPECIFICATION			
Style		H07RN-F	
Standard		EN50525-2-21	
Applications		Heavy duty rubber cable	
			
Construction Details:			
Test Item		Unit	5G4
Conductor	Material		Bare Copper
	Construction		56/0.284±0.01
	Conductor DC resistance at 20°C ≤	Ω/km	≤4.95
Core Insulation	Material		EPDM
	Avg. thickness	mm	1.0
	Min. thickness	mm	0.8
	Surface		Smooth
	Colors		Green/yellow,blue,brown,black,gre
lay	filler		Cotton yarn
Jacket	Material		CPE
	Avg. thickness	mm	2.2
	Min. thickness	mm	1.77
	Over Diameter	mm	16.9±0.8
	Surface		Smooth
	Colors		Black
marking	<VDE> 40015999 H07RN-F 450/750V 5G4mm ² RIFENG		