

## VOLTCRAFT - RELIABLE AND PRECISE. SINCE 1982.

For more than 40 years, our product range has been dynamically adapting to the constant changes in the industry. We commit to offering first-class quality to our customers while delivering an excellent cost-performance ratio. This philosophy remains the cornerstone of Voltcraft's success.



## ALKALINE BATTERY


| Item No.: | Pcs per pack |
|-----------|--------------|
| 2899769   | 2            |
| 3221601   | 5            |
| 2521372   | 10           |

### TECHNICAL DATA

|                       |                                                   |
|-----------------------|---------------------------------------------------|
| Type:                 | LR1130 (AG10 LR54)                                |
| Classification:       | Non-rechargeable                                  |
| Chemical system:      | Zn/KOH-H <sub>2</sub> O/MnO <sub>2</sub>          |
| Nominal voltage:      | 1.5 V                                             |
| Weight (approx.)      | 1.15 g                                            |
| Capacity:             | 45 mAh                                            |
| Loading:              | 15 kΩ (20 ±2 °C)                                  |
| Cut-off voltage:      | 1.2 V                                             |
| Operating conditions: | -18 to +50 °C<br>+10 to +35 °C (recommended)      |
| Storage conditions:   | +10 to +25 °C (max. 30 °C), <60 % RH              |
| Heavy metals:         | No added mercury (Hg), Cadmium (Cd), or Lead (Pb) |
| Compliant to:         | (EU) 2023/1542                                    |

For performance and safety, observe the operating / storage conditions. Capacity varies depending on the applied load, temperature, and cut-off voltage.

### DIMENSIONS (mm)

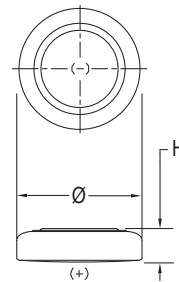

| Dimension | Min.  | Max.  |
|-----------|-------|-------|
| Ø         | 11.25 | 11.60 |
| H         | 2.75  | 3.05  |

