


Insulated Cable Ferrules, 400pcs DIN Color Coding (0.5-2.5mm²)

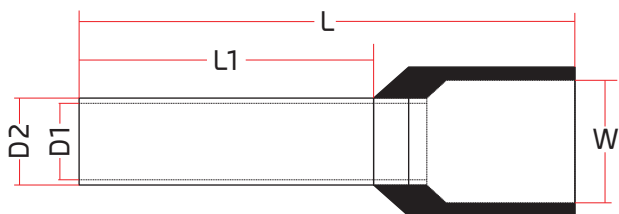

Technical Data:

Color type: DIN
 Terminal material: Copper
 Terminal coating: Tin
 Insulation material: PVC
 Max. voltage rating: 600V
 Max. temperature rating: 75°C

Wire Guide	Cross Section	Dimension (mm)					Color	Quantity
		L	L1	øD1	øD2	W		
22 AWG	0.50 mm ²	14.2 ±1.0	8.0 ±0.6	0.9 ±0.1	1.3 ±0.1	2.5 ±0.3	White	50 pcs
20 AWG	0.75 mm ²	15.1 ±1.0	8.0 ±0.6	1.2 ±0.1	1.5 ±0.2	2.8 ±0.3	Grey	100 pcs
18 AWG	1.00 mm ²	14.7 ±1.0	8.0 ±0.3	1.4 ±0.1	1.8 ±0.2	2.9 ±0.2	Red	100 pcs
16 AWG	1.50 mm ²	15.4 ±1.0	8.0 ±0.3	1.6 ±0.1	2.0 ±0.1	3.4 ±0.2	Black	100 pcs
14 AWG	2.50 mm ²	15.6 ±1.0	8.0 ±0.3	2.2 ±0.1	2.6 ±0.1	4.1 ±0.3	Blue	50 pcs