

N-19NVMe Slim Cage Introduction

NVMe Solution



1 x NVMe U.2 SSD (PCIe3.0 or PCIe4.0)

With 1 x mini SAS HD (SFF-8643) connector, intel spec, to reach the best NVMe U.2 SSD transmission performance upto 64Gbps.



N-19NVMe



Special Size Design


N-19NVMe is compact and suitable for the mini case solution.

Bracket for 3.5" HDD (Floppy) Size

N-19NVMe and BF-19 Bracket can fit in standard floppy (3.5" HDD size) space in any chassis.



[Please refer N-19NVMe19 for details](#)

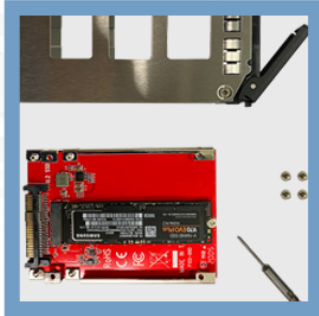

Trays for NVMe U.2 and optional kit for NVMe M.2 SSD

- (1) NVMe U.2 SSD supports upto 15mm height.
- (2) NVMe M.2 SSD must combine with **M2U01 adapter**. (Support 2230/ 2242/ 2260/ 2280.)

Tri-angle Metal Keylock

Each tray is with a tri-angle security keylock for the data inside the backplane cage.



LED Indication

Power LED for power On and off.
Access LED blinking for data accessing.

N-19NVME Specification

Form Factor	Half 5.25" Drive Bay Width Size
Support HDD Type	1 X 2.5" U.2/ U.3*/ M.2(with M2U03 Adapter) Up To 15mm (PCIe3.0/4.0 X4 32/64Gbps)
Interface	MiniSAS HD(SFF-8643) Connector X 1 15pin Power Connector X 1
LED Indication	Power On- Green HDD Access- Orange Blinking
Security Design	Metal Key Lock
Material	Metal Frame & Stainless HDD Tray
Fan	N/A
Operating System	Windows/ Linux/Mac
Product Dimension	141.9(L) X 72.5(W) X 21.0(H) Mm