


Item no.: 2903452 – Black
2903453 – Silver

Data Sheet

Turning knob aluminium (Ø x H): 25 mm x 16 mm
Inner bore dia.: 6.0 mm

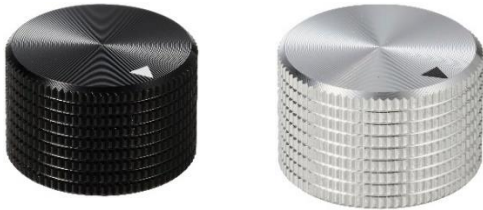

Technical data

Turning knob size (Ø x H): 25 mm x 16 mm

Inner bore diameter: 6 mm

Material: Aluminum

Operating & Storage temperature: -25 °C ~ +85 °C

Operating & Storage humidity: 20 %RH ~ 85 %RH

Drawing:

