




Part Number : [731335003](#)

Product Description : BNC 50 Ohm, Vertical PCB Jack Receptacle, 16.80mm Mounted Height

Series Number : 73133

Status : Active

Product Category : RF / Coaxial Connectors

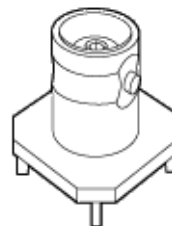

Documents & Resources

Drawings

[Drawing 731335003_sd.pdf](#)

Product Environment Compliance

Compliance

GADSL/IMDS	Not Relevant
China RoHS	Not Reviewed per SJ/T 11365-2006
EU ELV	Not Relevant
Low-Halogen Status	Not Reviewed per IEC 61249-2-21
REACH SVHC	Not Reviewed per D(2023)3788-DC (14 Jun 2023)
EU RoHS	Not Reviewed per EU 2015/863

Multiple Part Product Compliance Statements

- Eu RoHS
- REACH SVHC
- Low-Halogen

Multiple Part Industry Compliance Documents

- IPC 1752A Class C
- IPC 1752A Class D
- Molex Product Compliance Declaration
- IEC-62474
- chemSHERPA (xml)

EU RoHS Certificate of Compliance

Part Details

General

Status	Active
Category	RF / Coaxial Connectors
Series	73133
Description	BNC 50 Ohm, Vertical PCB Jack Receptacle, 16.80mm Mounted Height
Product Family	BNC Miniature RF Connectors and Cable Assemblies
Product Name	BNC
Style	PCB
Type	Miniature
UPC	800754313179

Electrical

Frequency	2 GHz
Impedance	50Ω
Power / Voltage	VOLTAGE: 500 Vrms@Sea Level

Physical

Cable Attachment	N/A
Gender	Jack
Keying to Mating Part	None
Net Weight	9.700/g
Orientation	Straight
Packaging Type	Tray
Panel Mount	No
Panel Mount Method	N/A
PCB Mounting	Through Hole
PCB Thickness - Recommended	3.20mm
Reverse Polar	No
Wire/Cable Type	N/A

Solder Process Data

Lead-Free Process Capability	SMC&WAVE
Max-Temp	260

This document was generated on Sep 26, 2023