


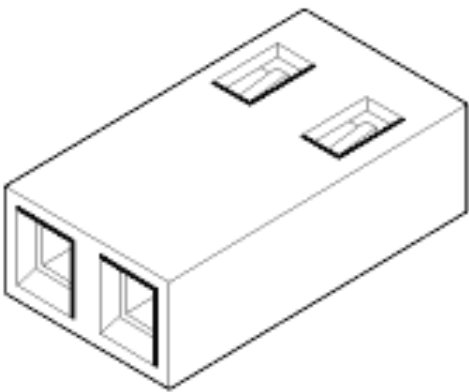

Part Number : [15291027](#)
Product Description : 2.54mm Pitch C-Grid
Shunt Terminal Housings, 0.762µm Gold (Au),
2 Circuits, with Pin Stop
Series Number : 7859
Status : Active
Product Category : Connector Accessories
Engineering Number : 7859-2A561N



Documents & Resources

Drawings

[Drawing 015291027_sd.pdf](#)
[Packaging Design Drawing PK-70873-0815-001.pdf](#)

3D Models and Design Files

[3D Model 015291027_stp.zip](#)

Specifications

[Product Specification PS-7859-001.pdf](#)
[Test Summary TS-7859-0001-001.pdf](#)

Product Environment Compliance

Compliance

GADSL/IMDS	Not Relevant
China RoHS	
EU ELV	Not Relevant
Low-Halogen Status	Not Low-Halogen per IEC 61249-2-21
REACH SVHC	Not Contained per D(2023)3788-DC (14 Jun 2023)
EU RoHS	Compliant per EU 2015/863

[Multiple Part Product Compliance Statements](#)

- Eu RoHS
- REACH SVHC

- Low-Halogen

Multiple Part Industry Compliance Documents

- IPC 1752A Class C
- IPC 1752A Class D
- Molex Product Compliance Declaration
- IEC-62474
- chemSHERPA (xml)

EU RoHS Certificate of Compliance

Part Details

General

Status	Active
Category	Connector Accessories
Series	7859
Description	2.54mm Pitch C-Grid Shunt Terminal Housings, 0.762µm Gold (Au), 2 Circuits, with Pin Stop
Component Type	Shunt
Product Family	C-Grid Connector Products
Product Name	C-Grid,C-Grid III,SL
UPC	800753604414

Agency

CSA	LR19980
UL	E29179

Electrical

Current - Maximum per Contact	5.0A
-------------------------------	------

Physical

Circuits (Loaded)	2
Circuits (maximum)	2
Color - Resin	Black
Flammability	94V-0
Lock to Mating Part	No
Material - Metal	Phosphor Bronze

Material - Resin	Polyester
Net Weight	0.164/g
Number of Rows	1
Packaging Type	Bag
Temperature Range - Operating	-40° to +105°C

Solder Process Data

Lead-Free Process Capability	N/A
------------------------------	-----

Use with Part(s)

Description	Part Number
C-Grid Vertical Dual Row Breakaway Headers	<u>70280</u>
C-Grid Vertical, Dual Row, Surface Mount Breakaway Headers	<u>71308</u>
C-Grid Right-Angle Dual Row Breakaway Headers	<u>70216</u>
C-Grid Right-Angle, Dual Row, Low Profile, Breakaway Headers	<u>71764</u>
KK 254 Vertical Breakaway Headers with Friction Lock	<u>42375</u>
KK 254 Right-Angle Surface Mount Compatible Breakaway Headers	<u>42377</u>
KK 254 Single Row Vertical Headers	<u>4030</u>