




Part Number : [22013137](#)
Product Description : KK 254 Crimp Housing,
Friction Ramp with Polarizing Ribs, 13 Circuits,
Natural
Series Number : 2695
Status : Active
Product Category : Connector Housings
Engineering Number : 2695-13RP

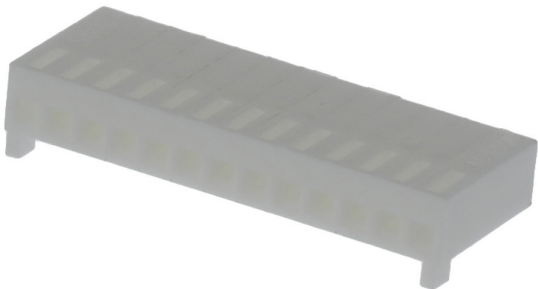

Documents & Resources

Drawings

[Drawing 022013137_sd.pdf](#)
[Packaging Design Drawing 26950002-PK-000.pdf](#)

3D Models and Design Files

[3D Model 022013137_stp.zip](#)

Specifications

[Product Specification PS-10-07-001.pdf](#)
[Test Summary TS-10-07-001.pdf](#)

Product Environment Compliance

Compliance

GADSL/IMDS	Not Relevant
China RoHS	
EU ELV	Not Relevant
Low-Halogen Status	Low-Halogen per IEC 61249-2-21
REACH SVHC	Not Contained per D(2023)3788-DC (14 Jun 2023)
EU RoHS	Compliant per EU 2015/863

Multiple Part Product Compliance Statements

- Eu RoHS
- REACH SVHC

- Low-Halogen

Multiple Part Industry Compliance Documents

- IPC 1752A Class C
- IPC 1752A Class D
- Molex Product Compliance Declaration
- IEC-62474
- chemSHERPA (xml)

EU RoHS Certificate of Compliance

Part Details

General

Status	Active
Category	Connector Housings
Series	2695
Description	KK 254 Crimp Housing, Friction Ramp with Polarizing Ribs, 13 Circuits, Natural
Application	Signal, Wire-to-Board
Product Family	KK Interconnect Systems
Product Name	KK 254
UPC	800753593473

Agency

CSA	LR19980
UL	E29179

Physical

Circuits (maximum)	13
Color - Resin	Natural (White)
Flammability	94V-0
Gender	Receptacle
Glow-Wire Capable	No
Lock to Mating Part	Yes
Material - Resin	Nylon
Net Weight	1.381/g
Number of Rows	1

Packaging Type	Bag
Panel Mount	No
Pitch - Mating Interface	2.54mm
Pitch - Termination Interface	2.54mm
Polarized to Mating Part	Yes
Stackable	No
Temperature Range - Operating	See Product Specification

Solder Process Data

Lead-Free Process Capability	N/A
------------------------------	-----

Mates With / Use With

Mates with Part(s)

Description	Part Number
KK 254 RPC Vertical Headers with Friction Lock	<u>171856</u>
KK 254 RPC Right-Angle Headers with Friction Lock	<u>171857</u>
KK 254 Single Row Vertical Headers	<u>4030</u>
KK 254 Vertical Breakaway Headers with Friction Lock	<u>42375</u>
KK 254 Right-Angle Breakaway Headers	<u>42376</u>
KK 254 Right-Angle Surface Mount Compatible Breakaway Headers	<u>42377</u>
KK 254 Vertical Single Row Solid Headers	<u>6373</u>
KK 254 Vertical Single Row Headers	<u>6410</u>

Use with Part(s)

Description	Part Number
Pre-Crimped Lead KK 254 Female-to-KK 254 Female, Tin (Sn) Plating, 150.00mm Length, 22 AWG, Black	<u>/content/molex/molex-dot-com/us/en/products/product-page.html/797580007.html</u>
Pre-Crimped Lead KK 254 Female-to-KK 254 Female, Tin (Sn) Plating, 300.00mm Length, 22 AWG, Black	<u>/content/molex/molex-dot-com/us/en/products/product-page.html/797580015.html</u>

KK 254 Female Crimp Terminals	<u>2759</u>
KK 254 Cat Ear Crimp Terminals	<u>41572</u>
KK 254 Female Crimp Terminals	<u>4809</u>
KK 254 Female Crimp Terminals	<u>6459</u>
KK 254 Female Crimp Terminals	<u>8088</u>

This document was generated on Sep 26, 2023