


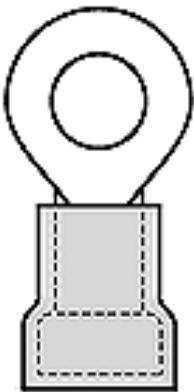

Part Number : [190580026](#)
Product Description : Avikrimp Ring Tongue
Terminal for 14-16 Heavy Duty AWG Wires
Series Number : 19058
Status : Active
Product Category : Ring and Spade Terminals
Engineering Number : B-801-76HD



Documents & Resources

Drawings

[Drawing 190580026_sd.pdf](#)

3D Models and Design Files

[3D Model 190580026_stp.zip](#)

Specifications

[Product Specification PS-19902-013-001.pdf](#)

[Product Specification PS-19902-011-001.pdf](#)

Product Environment Compliance

Compliance

GADSL/IMDS	Not Relevant
China RoHS	
EU ELV	Not Relevant
Low-Halogen Status	Low-Halogen per IEC 61249-2-21
REACH SVHC	Not Contained per D(2023)3788-DC (14 Jun 2023)
EU RoHS	Compliant per EU 2015/863

[Multiple Part Product Compliance Statements](#)

- Eu RoHS
- REACH SVHC
- Low-Halogen

[Multiple Part Industry Compliance Documents](#)

- IPC 1752A Class C
- IPC 1752A Class D
- Molex Product Compliance Declaration
- IEC-62474
- chemSHERPA (xml)

EU RoHS Certificate of Compliance

Part Details

General

Status	Active
Category	Ring and Spade Terminals
Series	19058
Description	Avikrimp Ring Tongue Terminal for 14-16 Heavy Duty AWG Wires
Keyword	Ring Terminal, Ring Terminals
Product Family	Quixon Terminals
Product Name	Avikrimp
Type	Ring
UPC	800753059214

Agency

CSA	LR18689
UL	E32244

Physical

Barrel Type	Closed
Flammability	94V-0
Insulation	Nylon (PA)
Material - Plating Mating	Tin
Net Weight	4.362/g
Packaging Type	Bag
Plating min - Mating	2.540µm
Plating min - Termination	2.540µm
Stud Size	7/16" (M11)
Termination Interface Style	Crimp or Compression

Wire Insulation Diameter	5.70mm max.
Wire Size (AWG)	14, 16
Wire Size mm ²	1.30-2.00

Solder Process Data

Lead-Free Process Capability	N/A
------------------------------	-----

Application Tooling

Global

Description	Part Number
PremiumGrade Hand Crimp Tool for Avikrimp and Insulkrimp Terminals and Splices, 10-22 AWG and 6.0-0.5mm ² (Rings, Spades, Hooks, Block Spades and Flanged Spades)	<u>0640010100</u>
Crimp Head for the AT-200 Pneumatic Hand Tool	<u>0640050100</u>
ServiceGrade Hand Crimp Tool for Field Repair only, for production use our PremiumGrade Tool	<u>0640160036</u>