


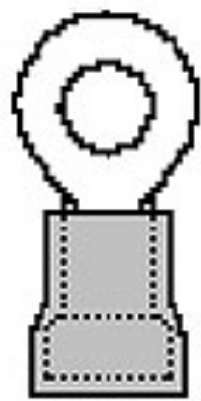

Part Number : [190730019](#)
Product Description : Avikrimp Ring Tongue
Terminal for 18 to 22 AWG Wire, Stud Size 10
(M5), Length 22.00mm, Mylar Tape Carrier
Series Number : 19073
Status : Active
Product Category : Ring and Spade Terminals
Engineering Number : AA-821-10T



Documents & Resources

Drawings

[Drawing 190730019_sd.pdf](#)

3D Models and Design Files

[3D Model 190730019_stp.zip](#)

Specifications

[Product Specification PS-19902-011-001.pdf](#)

Product Environment Compliance

Compliance

GADSL/IMDS	Not Relevant
China RoHS	
EU ELV	Not Relevant
Low-Halogen Status	Low-Halogen per IEC 61249-2-21
REACH SVHC	Not Contained per D(2023)3788-DC (14 Jun 2023)
EU RoHS	Compliant per EU 2015/863

[Multiple Part Product Compliance Statements](#)

- Eu RoHS
- REACH SVHC
- Low-Halogen

[Multiple Part Industry Compliance Documents](#)

- IPC 1752A Class C
- IPC 1752A Class D
- Molex Product Compliance Declaration
- IEC-62474
- chemSHERPA (xml)

EU RoHS Certificate of Compliance

Part Details

General

Status	Active
Category	Ring and Spade Terminals
Series	19073
Description	Avikrimp Ring Tongue Terminal for 18 to 22 AWG Wire, Stud Size 10 (M5), Length 22.00mm, Mylar Tape Carrier
Keyword	Ring Terminal, Ring Terminals
Product Family	Solderless Terminals
Product Name	Avikrimp
Type	Ring
UPC	800753075085

Agency

CSA	LR18689
UL	E32244

Physical

Barrel Type	Closed
Flammability	94V-2
Insulation	Nylon (PA)
Material - Plating Mating	Tin
Net Weight	0.771/g
Packaging Type	Adhesive Tape on Reel
Stud Size	10 (M5)
Wire Insulation Diameter	3.60mm max.
Wire Size (AWG)	18, 20, 22

Wire Size mm ²	0.35-0.80
---------------------------	-----------

Solder Process Data

Lead-Free Process Capability	N/A
------------------------------	-----

Application Tooling

Global

Description	Part Number
ATP Crimp Dies for the Tape Crimp Module and ATP-101 & 301 Press	<u>0192880023</u>
Mini-Mac Pneumatic Applicator for Ring and Spade Terminals, 18-22 AWG	<u>0638851300</u>