




Part Number : [191930149](#)
Product Description : VersaKrimp Ring
Tongue Terminal for 8 AWG Wire, Stud Size 10
(M5)
Series Number : 19193
Status : Active
Product Category : Ring and Spade Terminals
Engineering Number : D-350-10

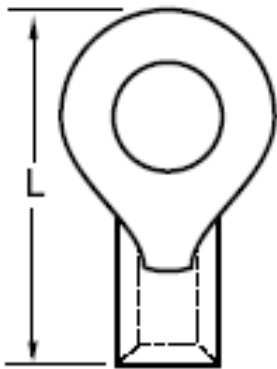

Documents & Resources

Drawings
[Drawing 191930149_sd.pdf](#)

Specifications
[Product Specification PS-19902-011-001.pdf](#)
[Product Specification PS-19902-013-001.pdf](#)

Product Environment Compliance

Compliance

GADSL/IMDS	Not Relevant
China RoHS	
EU ELV	Not Relevant
Low-Halogen Status	Low-Halogen per IEC 61249-2-21
REACH SVHC	Not Contained per D(2023)3788-DC (14 Jun 2023)
EU RoHS	Compliant per EU 2015/863

Multiple Part Product Compliance Statements
- Eu RoHS
- REACH SVHC
- Low-Halogen

Multiple Part Industry Compliance Documents
- IPC 1752A Class C
- IPC 1752A Class D

- Molex Product Compliance Declaration
- IEC-62474
- chemSHERPA (xml)

EU RoHS Certificate of Compliance

Part Details

General

Status	Active
Category	Ring and Spade Terminals
Series	19193
Description	VersaKrimp Ring Tongue Terminal for 8 AWG Wire, Stud Size 10 (M5)
Keyword	Ring Terminal, Ring Terminals
Product Family	VersaKrimp Terminals and Splices
Product Name	VersaKrimp
Type	Ring
UPC	800753039469

Agency

CSA	LR18689
UL	E32244

Physical

Barrel Type	Closed - Brazed
Insulation	None
Material - Plating Mating	Tin
Net Weight	3.200/g
Packaging Type	Bag
Stud Size	10 (M5)
Termination Interface Style	Crimp or Compression
Wire Size (AWG)	8
Wire Size mm ²	6.60-10.50

Application Tooling

Global

Description	Part Number
Manual Putt Pump Hydraulic System, Die set required	<u>0192860117</u>
Die Set (Large) for the HHLS Hydraulic Crimper	<u>0192900001</u>
Manual tool for Crimping non-insulated 8AWG thru 4/0 Terminals	<u>0192940008</u>
Hydraulic Dieless Crimping Tool	<u>0638161700</u>
PremiumGrade Hand Crimp Tool for 2-8 AWG Terminals	<u>0640013900</u>
RHT1080 Hand Crimp Tool	<u>0640034400</u>
Square "DIN" style dies for 8 AWG	<u>0640037670</u>
Crimp Head for the AT-200 Pneumatic Hand Tool	<u>0640074400</u>