




Part Number : [191930222](#)
Product Description : VersaKrimp Ring
Tongue Terminal for 6 AWG Wire
Series Number : 19193
Status : Active
Product Category : Ring and Spade Terminals
Engineering Number : E-357-56T

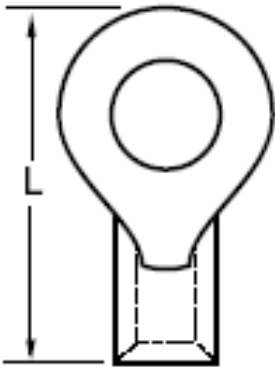

Documents & Resources

Drawings

[Drawing 191930222_sd.pdf](#)

Specifications

[Product Specification PS-19902-011-001.pdf](#)

[Product Specification PS-19902-015-001.pdf](#)

Product Environment Compliance

Compliance

GADSL/IMDS	Not Relevant
China RoHS	
EU ELV	Not Relevant
Low-Halogen Status	Low-Halogen per IEC 61249-2-21
REACH SVHC	Not Contained per D(2023)3788-DC (14 Jun 2023)
EU RoHS	Compliant per EU 2015/863

[Multiple Part Product Compliance Statements](#)

- Eu RoHS
- REACH SVHC
- Low-Halogen

[Multiple Part Industry Compliance Documents](#)

- IPC 1752A Class C
- IPC 1752A Class D

- Molex Product Compliance Declaration
- IEC-62474
- chemSHERPA (xml)

EU RoHS Certificate of Compliance

Part Details

General

Status	Active
Category	Ring and Spade Terminals
Series	19193
Description	VersaKrimp Ring Tongue Terminal for 6 AWG Wire
Keyword	Ring Terminal, Ring Terminals
Product Family	VersaKrimp Terminals and Splices
Product Name	VersaKrimp
Type	Ring
UPC	800753040021

Agency

CSA	LR18689
UL	E32244

Physical

Barrel Type	Closed - Brazed
Insulation	None
Material - Plating Mating	Tin
Net Weight	5.860/g
Packaging Type	Adhesive Tape on Reel
Plating min - Mating	2.540µm
Plating min - Termination	2.540µm
Stud Size	5/16" (M8)
Termination Interface Style	Crimp or Compression
Wire Size (AWG)	6

Application Tooling

Global

Description	Part Number
ATP Crimp Dies for the Tape Crimp Module and ATP-101 & 301 Press	<u>0190270145</u>
Crimp Dies for 6 AWG Versakrimp Mylar Tape, use with Tape Crimp Module and TM-4000 Crimp Press	<u>0190472010</u>

This document was generated on Sep 26, 2023