


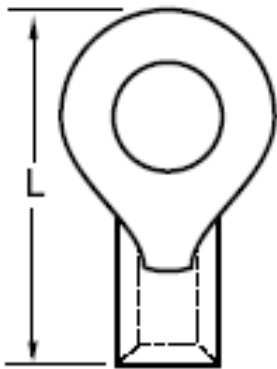

**Part Number :** [191930247](#)  
**Product Description :** VersaKrimp Ring  
Tongue Terminal for 6 AWG Wire, Stud Size 10  
(M5), Mylar Tape Carrier  
**Series Number :** 19193  
**Status :** Active  
**Product Category :** Ring and Spade Terminals  
**Engineering Number :** E-360-10T



## Documents & Resources

### Drawings

[Drawing 191930247\\_sd.pdf](#)

### Specifications

[Product Specification PS-19902-011-001.pdf](#)

[Product Specification PS-19902-015-001.pdf](#)

## Product Environment Compliance

### Compliance

|                    |                                                                                       |
|--------------------|---------------------------------------------------------------------------------------|
| GADSL/IMDS         | Not Relevant                                                                          |
| China RoHS         |  |
| EU ELV             | Not Relevant                                                                          |
| Low-Halogen Status | Low-Halogen per IEC 61249-2-21                                                        |
| REACH SVHC         | Not Contained per D(2023)3788-DC (14 Jun 2023)                                        |
| EU RoHS            | Compliant per EU 2015/863                                                             |

### Multiple Part Product Compliance Statements

- Eu RoHS
- REACH SVHC
- Low-Halogen

### Multiple Part Industry Compliance Documents

- IPC 1752A Class C
- IPC 1752A Class D

- Molex Product Compliance Declaration
- IEC-62474
- chemSHERPA (xml)

## EU RoHS Certificate of Compliance

---

### Part Details

#### General

|                |                                                                                       |
|----------------|---------------------------------------------------------------------------------------|
| Status         | Active                                                                                |
| Category       | Ring and Spade Terminals                                                              |
| Series         | 19193                                                                                 |
| Description    | VersaKrimp Ring Tongue Terminal for 6 AWG Wire, Stud Size 10 (M5), Mylar Tape Carrier |
| Keyword        | Ring Terminal, Ring Terminals                                                         |
| Product Family | VersaKrimp Terminals and Splices                                                      |
| Product Name   | VersaKrimp                                                                            |
| Type           | Ring                                                                                  |
| UPC            | 800753040298                                                                          |

#### Agency

|     |         |
|-----|---------|
| CSA | LR18689 |
| UL  | E32244  |

#### Physical

|                           |                       |
|---------------------------|-----------------------|
| Barrel Type               | Closed - Brazed       |
| Insulation                | None                  |
| Material - Plating Mating | Tin                   |
| Net Weight                | 5.907/g               |
| Packaging Type            | Adhesive Tape on Reel |
| Stud Size                 | 10 (M5)               |
| Wire Size (AWG)           | 6                     |
| Wire Size mm <sup>2</sup> | 6.60-10.50            |

---

#### Application Tooling

## Global

| Description                                                                                    | Part Number       |
|------------------------------------------------------------------------------------------------|-------------------|
| ATP Crimp Dies for the Tape Crimp Module and ATP-101 & 301 Press                               | <u>0190270145</u> |
| Crimp Dies for 6 AWG Versakrimp Mylar Tape, use with Tape Crimp Module and TM-4000 Crimp Press | <u>0190472010</u> |

---

This document was generated on Sep 26, 2023