




Part Number : [351510619](#)

Product Description : VersaBlade Hybrid Plug Housing, 6 Circuits, Positive Lock, Natural, Glow-Wire Capable

Series Number : 35151

Status : Active

Product Category : Connector Housings

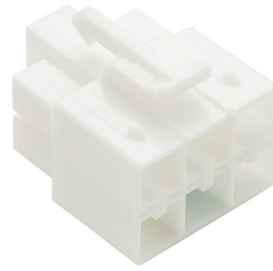

---

## Documents & Resources

### Drawings

[Drawing 351510619\\_sd.pdf](#)

### 3D Models and Design Files

[3D Model 351510619\\_stp.zip](#)

### Specifications

[Application Specification 351500000AS\\_ENG-000.pdf](#)

[Packaging Specification PK-35151-006-001.pdf](#)

[Product Specification PS-35150-003-001.pdf](#)

---

## Product Environment Compliance

### Compliance

GADSL/IMDS	Not Relevant
China RoHS	
EU ELV	Not Relevant
Low-Halogen Status	Not Low-Halogen per IEC 61249-2-21
REACH SVHC	Not Contained per D(2023)3788-DC (14 Jun 2023)
EU RoHS	Compliant per EU 2015/863

### [Multiple Part Product Compliance Statements](#)

- Eu RoHS
- REACH SVHC
- Low-Halogen

### [Multiple Part Industry Compliance Documents](#)

- IPC 1752A Class C

- IPC 1752A Class D
- Molex Product Compliance Declaration
- IEC-62474
- chemSHERPA (xml)

EU RoHS Certificate of Compliance

---

## Part Details

### General

Status	Active
Category	Connector Housings
Series	35151
Description	VersaBlade Hybrid Plug Housing, 6 Circuits, Positive Lock, Natural, Glow-Wire Capable
Application	Power, Wire-to-Wire
Product Family	VersaBlade Wire-to-Wire Connector System
Product Name	VersaBlade
UPC	756054257128

### Agency

CSA	LR19980
UL	E29179

### Physical

Breakaway	No
Circuits (maximum)	6
Color - Resin	Natural
Flammability	94V-0
Gender	Plug
Glow-Wire Capable	Yes
Keying to Mating Part	None
Lock to Mating Part	Yes
Material - Resin	PET/PC
Net Weight	4.226/g
Number of Rows	2

Packaging Type	Bag
Panel Mount	No
Pitch - Mating Interface	7.30mm
Pitch - Termination Interface	7.30mm
Polarized to Mating Part	Yes
Stackable	No
Temperature Range - Operating	-40° to +110°C

---

## Mates With / Use With

### Mates with Part(s)

Description	Part Number
VersaBlade Hybrid Receptacles Housings and TPAs	<u>35150</u>

### Use with Part(s)

Description	Part Number
VersaBlade Terminal Position Assurance (TPA) Retainer, 7.30mm Pitch, 3 Circuits, Natural	<a href="/content/molex/molex-dot-com/us/en/products/product-page.html/351500390.html">/content/molex/molex-dot-com/us/en/products/product-page.html/351500390.html</a>
VersaBlade Terminal Position Assurance (TPA) Retainer, 7.30mm Pitch, 3 Circuits, Red	<a href="/content/molex/molex-dot-com/us/en/products/product-page.html/351500392.html">/content/molex/molex-dot-com/us/en/products/product-page.html/351500392.html</a>
VersaBlade Terminal Position Assurance (TPA) Retainer, 7.30mm Pitch, 3 Circuits, Yellow	<a href="/content/molex/molex-dot-com/us/en/products/product-page.html/351500393.html">/content/molex/molex-dot-com/us/en/products/product-page.html/351500393.html</a>
VersaBlade Terminal Position Assurance (TPA) Retainer, 7.30mm Pitch, 3 Circuits, Blue	<a href="/content/molex/molex-dot-com/us/en/products/product-page.html/351500394.html">/content/molex/molex-dot-com/us/en/products/product-page.html/351500394.html</a>
VersaBlade Male Crimp Terminals	<u>35745</u>
VersaBlade Female Crimp Terminals	<u>35746</u>
VersaBlade Female Crimp Terminals	<u>35748</u>