


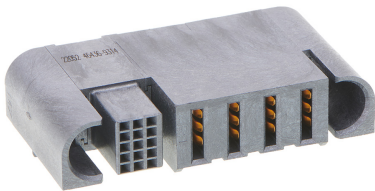

**Part Number :** [464369314](#)  
**Product Description :** EXTreme Ten60Power  
Right-Angle Receptacle with Side Guides, 4 DC  
Power Circuits, 15 Signal Circuits, Press Fit Tail  
**Series Number :** 46436  
**Status :** Active  
**Product Category :** Board-to-Board  
Connectors



## Documents & Resources

**Drawings**  
[Drawing 464369314\\_sd.pdf](#)  
[Packaging Design Drawing 464361001-PK-000.pdf](#)

**3D Models and Design Files**  
[3D Model 464369314\\_stp.zip](#)

**Specifications**  
[Product Specification PS-46436-100-001.pdf](#)  
[Test Summary 464361000-TS-000.pdf](#)

## Product Environment Compliance

### Compliance

|                    |                                                                                       |
|--------------------|---------------------------------------------------------------------------------------|
| GADSL/IMDS         | Compliant with Exemption 44; 34; 33                                                   |
| China RoHS         |  |
| EU ELV             | Not Relevant                                                                          |
| Low-Halogen Status | Low-Halogen per IEC 61249-2-21                                                        |
| REACH SVHC         | Not Contained per D(2023)3788-DC (14 Jun 2023)                                        |
| EU RoHS            | Compliant per EU 2015/863                                                             |

[Multiple Part Product Compliance Statements](#)  
- Eu RoHS  
- REACH SVHC  
- Low-Halogen

[Multiple Part Industry Compliance Documents](#)

- IPC 1752A Class C
- IPC 1752A Class D
- Molex Product Compliance Declaration
- IEC-62474
- chemSHERPA (xml)

## EU RoHS Certificate of Compliance

---

### Part Details

#### General

|                |                                                                                                                     |
|----------------|---------------------------------------------------------------------------------------------------------------------|
| Status         | Active                                                                                                              |
| Category       | Board-to-Board Connectors                                                                                           |
| Series         | 46436                                                                                                               |
| Description    | EXTreme Ten60Power Right-Angle Receptacle with Side Guides, 4 DC Power Circuits, 15 Signal Circuits, Press Fit Tail |
| Application    | Board-to-Board, Power, Signal                                                                                       |
| Comments       | See Product Specification for details                                                                               |
| Component Type | PCB Receptacle                                                                                                      |
| Product Family | EXTreme Ten60 High-Power Connectors                                                                                 |
| Product Name   | EXTreme Ten60Power                                                                                                  |
| UPC            | 195842670815                                                                                                        |

#### Agency

|    |        |
|----|--------|
| UL | E29179 |
|----|--------|

#### Electrical

|                               |                   |
|-------------------------------|-------------------|
| Current - Maximum per Contact | 60.0A             |
| Grounding to PCB              | No                |
| Voltage - Maximum             | 600V AC / 250V DC |

#### Physical

|                    |       |
|--------------------|-------|
| Circuits (Loaded)  | 19    |
| Circuits (maximum) | 19    |
| Color - Resin      | Black |

|                                |                              |
|--------------------------------|------------------------------|
| Durability (mating cycles max) | 200                          |
| Flammability                   | 94V-0                        |
| Glow-Wire Capable              | No                           |
| Guide to Mating Part           | Side, Yes                    |
| Keying to Mating Part          | None                         |
| Lock to Mating Part            | No                           |
| Mated Height                   | 10.00mm                      |
| Material - Metal               | High Conductivity Copper     |
| Material - Plating Mating      | Gold                         |
| Material - Plating Termination | Tin                          |
| Material - Resin               | Liquid Crystal Polymer       |
| Net Weight                     | 17.565/g                     |
| Number of Rows                 | 1, 5                         |
| Orientation                    | Right Angle                  |
| Packaging Type                 | Tray                         |
| PC Tail Length                 | 2.50mm, 3.28mm               |
| PCB Locator                    | Yes                          |
| PCB Retention                  | Yes                          |
| PCB Thickness - Recommended    | 1.58mm                       |
| Pitch - Mating Interface       | 2.00mm, 5.50mm               |
| Plating min - Mating           | 0.762µm                      |
| Plating min - Termination      | 2.540µm                      |
| Polarized to Mating Part       | Yes                          |
| Polarized to PCB               | Yes                          |
| (p)ower-(s)ignal Configuration | 4p - 15s                     |
| Stackable                      | No                           |
| Temperature Range - Operating  | -40° to +105°C               |
| Termination Interface Style    | Through Hole - Compliant Pin |

---

## Mates With / Use With

### Mates with Part(s)

| Description | Part Number |
|-------------|-------------|
|-------------|-------------|

|                                                                                                                        |                   |
|------------------------------------------------------------------------------------------------------------------------|-------------------|
| EXTreme Ten60Power Right-Angle<br>Plug with Side Guides, 4 DC Power<br>Circuits, 15 Signal Circuits, Press Fit<br>Tail | <u>0464379314</u> |
|------------------------------------------------------------------------------------------------------------------------|-------------------|

---

This document was generated on Sep 26, 2023