


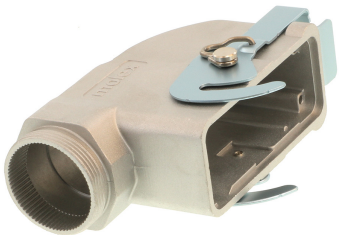

Part Number : [586961010](#)
Product Description : HMC Rectangular Industrial Hood, Multi-Module Type, Right-Angle, External Thread, 36 Circuits
Series Number : 58696
Status : Planned for Obsolescence
Product Category : I/O Connectors



Documents & Resources

Product Environment Compliance

Compliance

GADSL/IMDS	Product not active
China RoHS	Product not active
EU ELV	Product not active
Low-Halogen Status	Product not active
REACH SVHC	Product not active
EU RoHS	Product not active

Multiple Part Product Compliance Statements

- Eu RoHS
- REACH SVHC
- Low-Halogen

Multiple Part Industry Compliance Documents

- IPC 1752A Class C
- IPC 1752A Class D
- Molex Product Compliance Declaration
- IEC-62474
- chemSHERPA (xml)

EU RoHS Certificate of Compliance

Part Details

General

Status	Planned for Obsolescence
--------	--------------------------

Category	I/O Connectors
Series	58696
Description	HMC Rectangular Industrial Hood, Multi-Module Type, Right-Angle, External Thread, 36 Circuits
Application	Panel-Mount
Component Type	Hood
Product Family	HMC Heavy Duty Rectangular Connectors
Product Name	HMC
Type	N/A
UPC	756054376102

Electrical

Current - Maximum per Contact	4.5A
Shielded	No
Voltage - Maximum	300V DC

Physical

Boot Color	N/A
Circuits (Loaded)	N/A
Circuits (maximum)	36
Durability (mating cycles max)	50
Gender	Plug
Lock to Mating Part	Yes
Material - Metal	Aluminum, Stainless Steel
Material - Plating Mating	N/A
Net Weight	211198.660/mg
Orientation	Right Angle
Packaging Type	Bag
Panel Mount	N/A
Pitch - Mating Interface	N/A
Polarized to Mating Part	Yes
Polarized to PCB	N/A
Temperature Range - Operating	-55° to +125°C
Termination Interface Style	N/A

Waterproof / Dustproof	Yes
Waterproof / Dustproof Type	IP65