


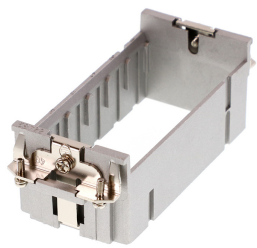

Part Number : [587210010](#)
Product Description : HMC Rectangular Industrial Hood Bracket, Multi-Module Type, 48-72 Circuits, Type A Polarization
Series Number : [58721](#)
Status : Planned for Obsolescence
Product Category : [I/O Connectors](#)



Documents & Resources

Product Environment Compliance

Compliance

GADSL/IMDS	Product not active
China RoHS	Product not active
EU ELV	Product not active
Low-Halogen Status	Product not active
REACH SVHC	Product not active
EU RoHS	Product not active

Multiple Part Product Compliance Statements

- Eu RoHS
- REACH SVHC
- Low-Halogen

Multiple Part Industry Compliance Documents

- IPC 1752A Class C
- IPC 1752A Class D
- Molex Product Compliance Declaration
- IEC-62474
- chemSHERPA (xml)

EU RoHS Certificate of Compliance

Part Details

General

Status	Planned for Obsolescence
--------	--------------------------

Category	I/O Connectors
Series	58721
Description	HMC Rectangular Industrial Hood Bracket, Multi-Module Type, 48-72 Circuits, Type A Polarization
Application	Panel-Mount
Component Type	Hood Bracket
Product Family	HMC Heavy Duty Rectangular Connectors
Product Name	HMC
Type	N/A
UPC	800753921023

Electrical

Current - Maximum per Contact	12.0A, 20.0A
Voltage - Maximum	250V AC

Physical

Circuits (Loaded)	48
Circuits (maximum)	48
Lock to Mating Part	Yes
Material - Plating Mating	N/A
Net Weight	46221.300/mg
Orientation	Vertical
Packaging Type	Bag
Panel Mount	N/A
Pitch - Mating Interface	N/A
Polarized to Mating Part	Yes
Temperature Range - Operating	-55° to +125°C
Termination Interface Style	N/A
Waterproof / Dustproof	Yes
Waterproof / Dustproof Type	IP65