



Part Number : [1301480108](#)


Product Description : Safeway Duplex
Corrosion-Resistant Receptacle, Heavy Grade
Corrosion-Resistant, 2 Pole/3 Wire, NEMA 6-
20, 250V

Series Number : 130148

Status : Active

Product Category : Wiring Devices

Engineering Number : 5462DWCR

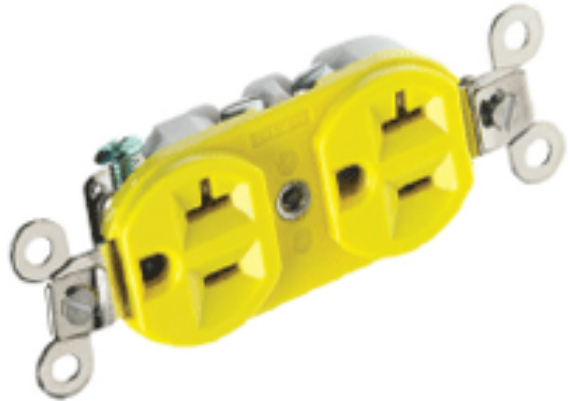

Documents & Resources

Drawings

[Drawing 1301480108_sd.pdf](#)

Product Environment Compliance

Compliance

| | |
|--------------------|--------------|
| China RoHS | Not Reviewed |
| EU ELV | Not Reviewed |
| Low-Halogen Status | Not Reviewed |
| REACH SVHC | Not Reviewed |
| EU RoHS | Not Reviewed |

Multiple Part Product Compliance Statements

- Eu RoHS
- REACH SVHC
- Low-Halogen

Multiple Part Industry Compliance Documents

- IPC 1752A Class C
- IPC 1752A Class D
- Molex Product Compliance Declaration
- IEC-62474
- chemSHERPA (xml)

EU RoHS Certificate of Compliance

Part Details

General

| | |
|--------------------|--|
| Status | Active |
| Category | Wiring Devices |
| Series | 130148 |
| Description | Safeway Duplex Corrosion-Resistant Receptacle, Heavy Grade Corrosion-Resistant, 2 Pole/3 Wire, NEMA 6-20, 250V |
| IP Rating | N/A |
| NEMA Configuration | NEMA 6-20 |
| Product Family | Heavy-Duty Industrial Wiring Devices |
| Product Name | Safeway |
| Specialty | N/A |
| Type | Receptacle |
| UPC | 78678871896 |

Agency

| | |
|----|--------|
| UL | E46237 |
|----|--------|

Electrical

| | |
|-------------------------------|-------|
| Current - Maximum per Contact | 20.0A |
| GFCI | No |
| Voltage - Maximum | 250V |

Physical

| | |
|-------------------|---------------|
| Cord Type | N/A |
| Flange | No |
| Flip Lid | No |
| Gender | Female |
| Length | N/A |
| Lighted Connector | No |
| Locking Blade | No |
| Poles | 2-pole/3-wire |
| Receptacle Type | Duplex |

This document was generated on Sep 26, 2023