




Part Number : [2033879010](#)
Product Description : Impel Test Cable
Assembly, Loopback, 30 AWG
Series Number : 203387
Status : Active
Product Category : High-Speed Pluggable I/O
Cable Assemblies

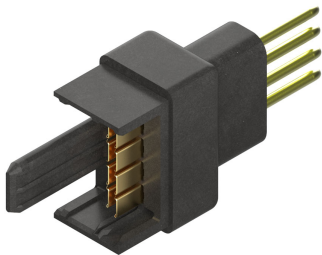

Documents & Resources

Drawings
[Drawing 2033879010_sd.pdf](#)
[Packaging Design Drawing 2033879010-PK.pdf](#)

Product Environment Compliance

Compliance

GADSL/IMDS	Not Relevant
China RoHS	
EU ELV	Not Relevant
Low-Halogen Status	Not Reviewed per IEC 61249-2-21
REACH SVHC	Not Reviewed per D(2023)3788-DC (14 Jun 2023)
EU RoHS	Compliant per EU 2015/863

Multiple Part Product Compliance Statements

- Eu RoHS
- REACH SVHC
- Low-Halogen

Multiple Part Industry Compliance Documents

- IPC 1752A Class C
- IPC 1752A Class D
- Molex Product Compliance Declaration
- IEC-62474
- chemSHERPA (xml)

EU RoHS Certificate of Compliance

Part Details

General

Status	Active
Category	High-Speed Pluggable I/O Cable Assemblies
Series	203387
Description	Impel Test Cable Assembly, Loopback, 30 AWG
Assembly Configuration	Single Ended Connector
Connector to Connector	Impel-to-Impel
Product Name	Impel
UPC	191128750493

Physical

Cable Length	LOOPBACK
Circuits (Loaded)	16
Circuits (maximum)	16
Color - Resin	Black
Gender	Male
Material - Metal	Copper Alloy
Material - Plating Mating	Gold
Material - Resin	Liquid Crystal Polymer
Net Weight	5.850/g
Packaging Type	Bag
Single Ended	Yes
Wire/Cable Type	Twinax
Wire Size (AWG)	30