


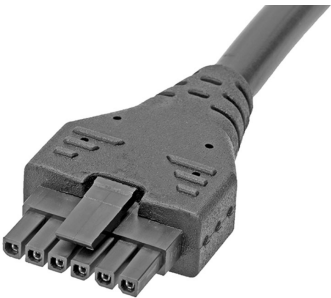

Part Number : [2147700610](#)
Product Description : Micro-Fit 3.0 Female-to-Micro-Fit 3.0 Female Off-the-Shelf (OTS) Cable Assembly, Single Row, 1.0m Length, Tin (Sn) Plating, 6 Circuits, Black
Series Number : 214770
Status : Active
Product Category : Power and Signal Cable Assemblies



Documents & Resources

Drawings
[Drawing 2147700610_sd.pdf](#)

Specifications
[Product Specification 4000356554-000.pdf](#)

Product Environment Compliance

Compliance

GADSL/IMDS	Not Relevant
China RoHS	
EU ELV	Not Relevant
Low-Halogen Status	Not Low-Halogen per IEC 61249-2-21
REACH SVHC	Not Contained per D(2023)3788-DC (14 Jun 2023)
EU RoHS	Compliant per EU 2015/863

Multiple Part Product Compliance Statements

- Eu RoHS
- REACH SVHC
- Low-Halogen

Multiple Part Industry Compliance Documents

- IPC 1752A Class C
- IPC 1752A Class D
- Molex Product Compliance Declaration
- IEC-62474

Part Details

General

Status	Active
Category	Power and Signal Cable Assemblies
Series	214770
Description	Micro-Fit 3.0 Female-to-Micro-Fit 3.0 Female Off-the-Shelf (OTS) Cable Assembly, Single Row, 1.0m Length, Tin (Sn) Plating, 6 Circuits, Black
Application	Power, Wire-to-Board, Wire-to-Wire
Assembly Configuration	Dual Ended Connectors
Connector to Connector	Micro-Fit 3.0 Both Ends
Product Family	Micro-Fit Connector System
Product Name	Micro-Fit 3.0
Type	Overmolded Assembly
UPC	193264653645

Electrical

Current - Maximum per Contact	8.5A
-------------------------------	------

Physical

Cable Length	1.0m
Circuits (Loaded)	6
Circuits (maximum)	6
Color - Resin	Black
Gender	Female-Female
Lock to Mating Part	Yes
Material - Metal	Phosphor Bronze
Material - Plating Mating	Tin
Material - Resin	Nylon
Net Weight	94.723/g
Number of Rows	1

Overmolded	Yes
Pitch - Mating Interface	3.00mm
Plating min - Mating	1.016µm
Single Ended	No
Termination Interface Style	Crimp or Compression
Wire/Cable Type	UL 2464
Wire Insulation Diameter	1.85mm max.
Wire Size (AWG)	20

Mates With / Use With

Mates with Part(s)

Description	Part Number
Micro-Fit 3.0 Single Row Plug Housings	<u>43640</u>
Micro-Fit TPA Single Row Plug Housings	<u>200875</u>
Micro-Fit 3.0 Single Row Headers	<u>43650</u>
Micro-Fit 3.0 Male-to-Micro-Fit 3.0 Male Off-the-Shelf (OTS) Cable Assemblies	<u>214752</u>
Micro-Fit 3.0 Male-to-Pigtail Off-the-Shelf (OTS) Cable Assemblies	<u>214753</u>