


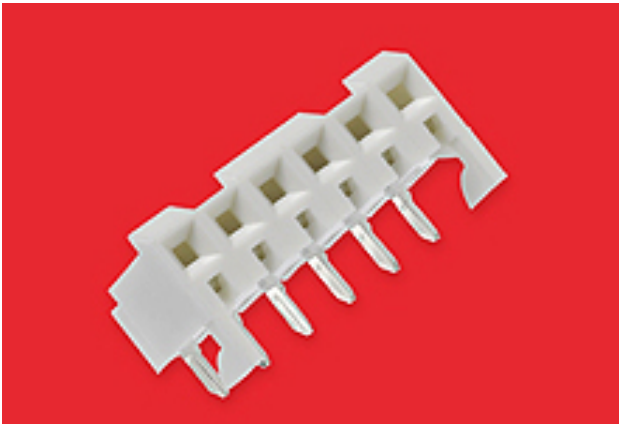

Part Number : [09483105](#)
Product Description : KK 396 PC Board Connector, Right-Angle, Polyester Connector, Gold (Au) Selective, 10 Circuits
Series Number : 41815
Status : Active
Product Category : PCB Headers and Receptacles
Engineering Number : A-41815-0433



Documents & Resources

Drawings

[Drawing 009483105_sd.pdf](#)
[Packaging Design Drawing PK-41815-001-000.pdf](#)

3D Models and Design Files

[3D Model 009483105_stp.zip](#)
[Symbol Footprint Data SYM-09-48-1104-001.zip](#)

Specifications

[Product Specification PS-08-50-001.pdf](#)

Product Environment Compliance

Compliance

GADSL/IMDS	Compliant with Exemption 44; 33
China RoHS	
EU ELV	Not Relevant
Low-Halogen Status	Not Low-Halogen per IEC 61249-2-21
REACH SVHC	Not Contained per D(2023)3788-DC (14 Jun 2023)
EU RoHS	Compliant per EU 2015/863

[Multiple Part Product Compliance Statements](#)

- Eu RoHS
- REACH SVHC

- Low-Halogen

Multiple Part Industry Compliance Documents

- IPC 1752A Class C
- IPC 1752A Class D
- Molex Product Compliance Declaration
- IEC-62474
- chemSHERPA (xml)

EU RoHS Certificate of Compliance

Part Details

General

Status	Active
Category	PCB Headers and Receptacles
Series	41815
Description	KK 396 PC Board Connector, Right-Angle, Polyester Connector, Gold (Au) Selective, 10 Circuits
Application	Board-to-Board, Power
Component Type	PCB Receptacle
Product Family	KK Interconnect Systems
Product Name	KK 396
UPC	800754903691

Agency

CSA	LR19980
UL	E29179

Electrical

Current - Maximum per Contact	5.0A
Voltage - Maximum	250V

Physical

Circuits (Loaded)	10
Circuits (maximum)	10
Color - Resin	Natural
Flammability	94V-0

Glow-Wire Capable	No
Lock to Mating Part	Yes
Material - Plating Mating	Gold
Material - Plating Termination	Tin
Material - Resin	Polyester
Net Weight	3.257/g
Number of Rows	1
Orientation	Right Angle
Packaging Type	Tray
PC Tail Length	3.68mm
PCB Locator	No
PCB Retention	Yes
Pitch - Mating Interface	3.96mm
Plating min - Mating	0.381µm
Plating min - Termination	2.540µm
Polarized to PCB	Yes
Temperature Range - Operating	See Product Specification
Termination Interface Style	Through Hole

Solder Process Data

Max-Duration	5
Lead-Free Process Capability	WAVE
Max-Cycle	1
Max-Temp	235

Mates With / Use With

Mates with Part(s)

Description	Part Number
KK 396 Vertical Breakaway Headers	<u>41661</u>
KK 396 Right-Angle Breakaway Headers	<u>41662</u>
KK 396 Vertical Square Pin Breakaway Headers	<u>41671</u>
KK 396 Right-Angle Friction Lock Breakaway Headers	<u>41672</u>

KK 396 Vertical Headers without Peg	<u>41771</u>
KK 396 Right-Angle Headers without Peg	<u>41772</u>
KK 396 Vertical Headers with Friction Lock	<u>41791</u>
KK 396 Right-Angle Headers with Friction Lock	<u>41792</u>
KK 396 Vertical Headers with Friction Lock	<u>42491</u>
KK 396 Right-Angle Headers with Friction Lock	<u>42492</u>
KK 396 Solid Vertical Headers with Friction Lock	<u>42891</u>