


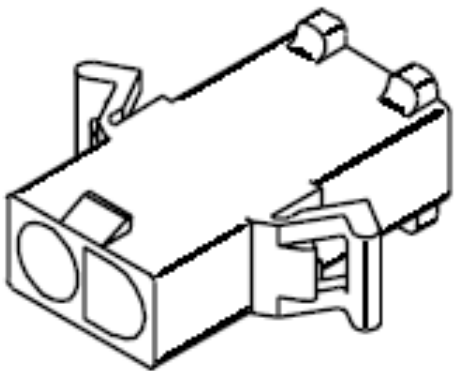

Part Number : [39036022](#)
Product Description : 2.36mm Diameter
Standard .093" Pin and Socket Plug Housing
with Positive Latch, UL 94V-2, without Panel
Mount, 2 Circuits
Series Number : 3191
Status : New Business Not Supported
Product Category : Connector Housings
Engineering Number : 3191-02P1



Documents & Resources

Product Environment Compliance

Compliance

GADSL/IMDS	Not Relevant
China RoHS	
EU ELV	Not Relevant
Low-Halogen Status	Low-Halogen per IEC 61249-2-21
REACH SVHC	Not Contained per D(2023)3788-DC (14 Jun 2023)
EU RoHS	Compliant per EU 2015/863

Multiple Part Product Compliance Statements

- Eu RoHS
- REACH SVHC
- Low-Halogen

Multiple Part Industry Compliance Documents

- IPC 1752A Class C
- IPC 1752A Class D
- Molex Product Compliance Declaration
- IEC-62474
- chemSHERPA (xml)

EU RoHS Certificate of Compliance

Part Details

General

Status	New Business Not Supported
Category	Connector Housings
Series	3191
Description	2.36mm Diameter Standard .093" Pin and Socket Plug Housing with Positive Latch, UL 94V-2, without Panel Mount, 2 Circuits
Application	Power, Wire-to-Board, Wire-to-Wire
Comments	Polarized to Mating Part
Product Family	Standard .093" Pin and Socket Connectors
Product Name	Standard .093"
UPC	800753756441

Agency

CSA	LR19980
UL	E29179

Electrical

Current - Maximum per Contact	12.0A
-------------------------------	-------

Physical

Breakaway	No
Circuits (maximum)	2
Color - Resin	Natural
Flammability	94V-2
Gender	Plug
Glow-Wire Capable	No
Keying to Mating Part	None
Lock to Mating Part	Yes
Material - Resin	Nylon
Net Weight	2408.600/mg
Number of Rows	1
Packaging Type	Bag

Panel Mount	No
Pitch - Mating Interface	6.70mm
Polarized to Mating Part	Yes
Stackable	No
Temperature Range - Operating	-40° to +105°C

This document was generated on Sep 26, 2023