



Part Number : [1731120303](#)


Product Description : FCT High Power Contact,
Male, Straight, Solder Cup, 0.80µm Gold
Mating Plating, 0.20µm Gold Termination
Plating, 40.0A, 8-12 AWG

Series Number : 173112

Status : Active

Product Category : D-Sub Contacts

Engineering Number : FMP051P103

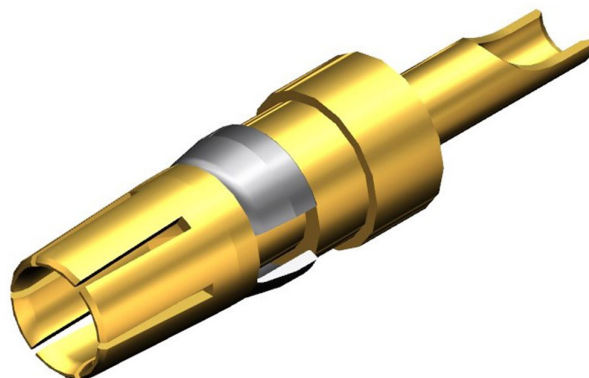

Documents & Resources

Drawings

[Drawing 1731120303_sd.pdf](#)

Product Environment Compliance

Compliance

GADSL/IMDS	Not Relevant
China RoHS	
EU ELV	Not Relevant
Low-Halogen Status	Not Reviewed per IEC 61249-2-21
REACH SVHC	Contains Lead per D(2023)3788-DC (14 Jun 2023)
EU RoHS	Compliant with Exemption 6(c) per EU 2015/863

Multiple Part Product Compliance Statements

- Eu RoHS
- REACH SVHC
- Low-Halogen

Multiple Part Industry Compliance Documents

- IPC 1752A Class C
- IPC 1752A Class D
- Molex Product Compliance Declaration
- IEC-62474

Part Details

General

Status	Active
Category	D-Sub Contacts
Series	173112
Description	FCT High Power Contact, Male, Straight, Solder Cup, 0.80µm Gold Mating Plating, 0.20µm Gold Termination Plating, 40.0A, 8-12 AWG
Contact Type	High Power
Product Family	FCT D-Sub Connectors
Product Name	FCT Products
Type	Mixed Layout
UPC	889056795838

Electrical

Current - Maximum per Contact	40.0A
-------------------------------	-------

Physical

Durability (mating cycles max)	500
Gender	Male
Material - Contact	Copper Alloy
Material - Plating Mating	Gold over Nickel
Material - Plating Termination	Gold over Nickel
Material - Retaining Clip	Copper Alloy
Net Weight	2.000/g
Orientation	Straight
Packaging Type	Bag
Plating min - Mating	0.800µm
Plating min - Termination	0.200µm
Temperature Range - Operating	-55° to +155°C
Termination Style	Solder Cup

Wire Size (AWG)	8, 10, 12
-----------------	-----------

Use with Part(s)

Description	Part Number
Use With	FCT Mixed Layout Connectors

Application Tooling

Global

Description	Part Number
FCT Removal Tool for Size 8 Contacts	<u>1731121747</u>
