


**BU-32614-@**  
(Stackable, Retractable Banana Plug)



- The BU-32614 has a spring-loaded retractable sheath that provides electrical protection when the cable is not mounted and slides into the housing when pressed into a non-shrouded jack. It also has a built-in banana jack that allows stacking other test leads with retractable or unshrouded 4mm banana plugs.
- Accepts 4mm banana plug and fits into 4mm banana jacks.
- Easy solder connection with wire between 18 and 14 AWG.
- Material:     Housing                     Nylon  
                  Contact                    Brass, beryllium copper
- Rating:       Current                    20 Amps  
                  Voltage                         Hands-free testing up to 1000 V @ 105°C
- Color: The “@” in the model number represents color. Available colors: -0 Black, -2 Red, -4 Yellow, -5 Green, -6 Blue, -8 Gray, -9 White
- RoHS 3 compliant, exemption 6c

Assembly Photo:

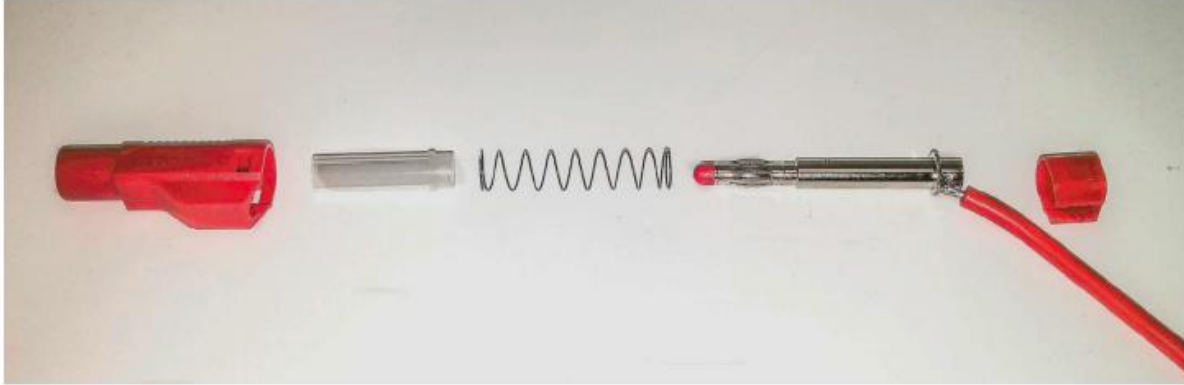

Note: Use very short wire strip length and solder just above the spring retainer.