


BU-P3846

(BNC Female to Female Adapter, Panel Mount)

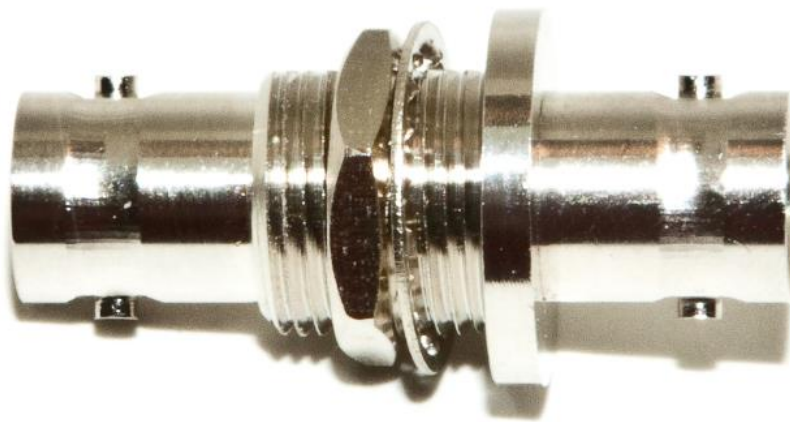

- Mueller's BU-P3846 is a female-female BNC adapter that mounts in panels up to 0.175" (4.45mm) thick.
- Recommended panel mounting hole is $\varnothing 0.50$ " (12.7mm).
- Material:

Body	Brass
Center contact	Gold-plated beryllium copper
Dielectric	PTFE
- Rating:

Voltage	Shield/contact, 500 VRMS Max.
Temperature	-65°C (-85°F) to 165°C (329°F)
Impedance	50 Ohms
- RoHS 3 compliant, exemption 6c