

## Avide LED Floor Lamp Remo 9W CCT Black

**Product code:** ABLFL-9W-REMO-B  
**Brand link:** [avidelighting.com/qr/ABLFL-9W-REMO-B](http://avidelighting.com/qr/ABLFL-9W-REMO-B)  
**ID:** AB-190518  
**Company name:** Armin Trade Kft.  
**Company address:** Kossuth utca 22 2/4, 4024 Debrecen



**Date of issue:** 2023-09-19

**Page:** 1/3

### SPECIFICATIONS

**EAN code:** 5999097919409  
**Warranty:** 2year(s)  
**Color:** Black  
**Material:** ALU+PC+FE  
**Working temperature:** -20 - + 40°C  
**Packaging:** 1/b 5/c 180/p  
**Certifications:** CE  
**Functions:** Changeable color temperature (5 steps), night light function, timer (60s, 10m), 5 step dimming, touch control panel and remote controller

### TECHNICAL DETAILS

**Wattage:** 9W  
**Voltage:** 100-240V  
**Built-in battery:**  
**Beam angle:** 170°  
**Dimmability:** Yes  
**Lumen output:** 500lm  
**Color temperature:** 5 000K  
**Lifetime:** 30 000h  
**Energy class:** G  
**Type of LED:**  
**Number of LEDs:**  
**CRI:** 80  
**IP standard:** IP20

### BOX PICTURE



## Avide LED Floor Lamp Remo 9W CCT Black

**Product code:** ABLFL-9W-REMO-B  
**Brand link:** [avidelighting.com/qr/ABLFL-9W-REMO-B](https://avidelighting.com/qr/ABLFL-9W-REMO-B)  
**ID:** AB-190518  
**Company name:** Armin Trade Kft.  
**Company address:** Kossuth utca 22 2/4, 4024 Debrecen

QR code:



Date of issue: 2023-09-19

Page: 2/3

### PRODUCT SIZE

Width: 220mm  
Height: 1 800mm  
Depth: 220mm

### CARDBOARD BOX

EAN: 5999097919409  
Packaging: 1/b 5/c 180/p  
Dimensions: 50mm x 440mm x 260mm  
Net weight: 2 566.5g  
Gross weight: 2 900g

### CARTON

EAN: 5999097919416  
Packaging: 1/b 5/c 180/p  
Dimensions: 460mm x 275mm x 280mm  
Net weight: 12.8325kg  
Gross weight: 14.5kg


### PALLET EXAMPLE

Height:  
Width: 120cm (std Euro pallet)  
Depth: 80cm (std Euro pallet)  
Cartons per pallet: 36carton/pallet  
Cartons per row:  
Net weight: 461.97kg  
Gross weight: 522kg

### PRODUCT PICTURE



### PRODUCT OUTLINE

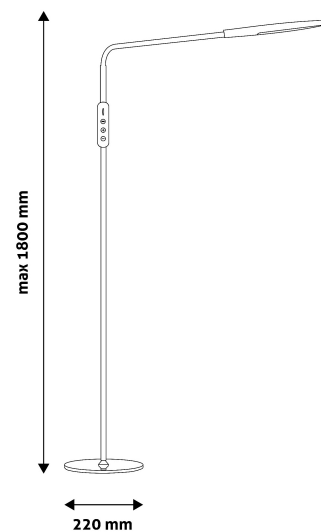

## Avide LED Floor Lamp Remo 9W CCT Black

<b>Product code:</b>	ABLFL-9W-REMO-B
<b>Brand link:</b>	<a href="https://avidelighting.com/qr/ABLFL-9W-REMO-B">avidelighting.com/qr/ABLFL-9W-REMO-B</a>
<b>ID:</b>	AB-190518
<b>Company name:</b>	Armin Trade Kft.
<b>Company address:</b>	Kossuth utca 22 2/4, 4024 Debrecen



**Date of issue:** 2023-09-19

**Page:** 3/3

### PRODUCT DESCRIPTION

The Avide REMO touch panel floor lamp gives a modern and stylish look to any room, let it be at home or in the office. It is remote controlled and offers a variety of functions.

Thanks to its adjustable color temperature, we can set it to the mood and needs most fitting for us. You can switch from warm white (3000 K) to cool white color temperature (6000 K) in five steps, until reaching the desired brightness.

We can also set a timer for switching the lamp off (with 60 and 10-second timer options). The product also features a night light function. An indicator light placed at the touch panel of the lamp shows if this function is activated.

The light fixture includes built-in LED light sources that cannot be replaced in the luminaire. The LEDs have a 9W output. With a height of 1 meter and 80 centimeters, it is perfectly suitable for lighting larger interior spaces. The product is available in white and black colors.