

Avide LED Strip Blister 12V 7.2W SMD5050 30LED RGB IP65 5m

Product code: ABLSBL12V5050-30RGB65
Brand link: avidelighting.com/qr/ABLSBL12V5050-30RGB65
ID: AB-190518
Company name: Armin Trade Kft.
Company address: Kossuth utca 22 2/4, 4024 Debrecen



QR code:
Date of issue: 2023-09-19
Page: 1/2


SPECIFICATIONS

EAN code: 5999097924267
Warranty: 2year(s)
Working temperature: -20-60°C
Packaging: 1/b 20/c 320/p
Certifications: CE

TECHNICAL DETAILS

Wattage: 7.2W
Voltage: 12V
Beam angle: 120°
Dimmability: Yes
Lumen output: 1 650lm
Color temperature:
Lifetime: 25 000h
Energy class:
Type of LED: SMD5050
LED / meter: 30LED/m
IP standard: IP65 / IP20

BOX PICTURE

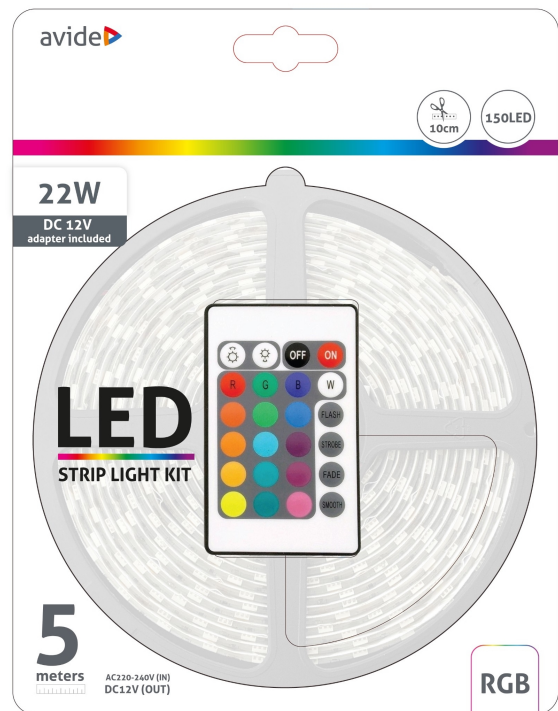

Avide LED Strip Blister 12V 7.2W SMD5050 30LED RGB IP65 5m

Product code: ABLSBL12V5050-30RGB65
Brand link: avidelighting.com/qr/ABLSBL12V5050-30RGB65
ID: AB-190518
Company name: Armin Trade Kft.
Company address: Kossuth utca 22 2/4, 4024 Debrecen



Date of issue: 2023-09-19

Page: 2/2

CARDBOARD BOX

EAN: 5999097924267
Packaging: 1/b 20/c 320/p
Dimensions: 210mm x 268mm x 78mm
Net weight: 388g
Gross weight: 388g

CARTON

EAN: 5999097924274
Packaging: 1/b 20/c 320/p
Dimensions: 500mm x 290mm x 435mm
Net weight: 7.76kg
Gross weight: 7.76kg

PALLET EXAMPLE

Height:
Width: 120cm (std Euro pallet)
Mepth: 80cm (std Euro pallet)
Cartons per pallet: 16carton/pallet
Cartons per row:
Net weight: 124.16kg
Gross weight: 124.16kg

BOX PICTURE

