
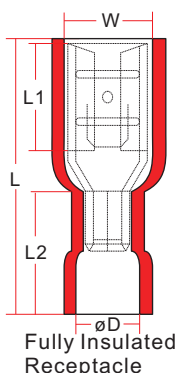
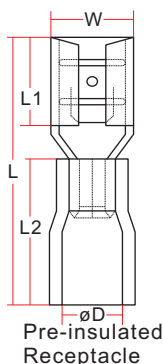


## Pre-insulated and Fully insulated Crimp Terminal, 575pcs Blade tab and Female receptacle, 0.5 - 2.5mm<sup>2</sup>

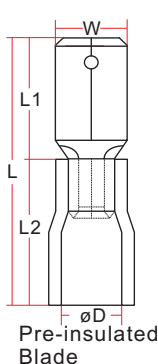

### Specification

- Terminal material : Brass
- Terminal plating : Tin
- Terminal thickness : 0.35 mm
- Rated current : Red - 10A max.  
: Blue - 15A max.
- Rated temperature : PVC - 75°C max.  
: Nylon - 105°C max.

Wire Guide	Cross Section	Insulator color	Tab size	Insulator	Dimension (mm)					Terminal	Quantity
					L	L1	L2	øD	W		
20-17 AWG	0.5-1.0 mm <sup>2</sup>	Red	2.8 x 0.8	PVC	18.3±1.0	7.8±0.5	10.5±0.5	3.8±0.3	2.8±0.3	Blade	50 Pcs
				PVC	19.0±1.0	8.5±0.5	10.5±0.5	3.8±0.3	3.8±0.3	Receptacle	50 Pcs
				Nylon	19.0±1.0	6.7±0.5	10.5±0.5	4.8±0.3	3.8±0.3	Receptacle	50 Pcs
			4.8 x 0.8	PVC	20.0±1.0	9.5±0.5	10.5±0.5	3.8±0.3	4.7±0.3	Blade	50 Pcs
				PVC	19.5±1.0	6.5±0.5	10.5±0.5	3.8±0.3	5.6±0.3	Receptacle	50 Pcs
				PVC	18.8±1.0	6.5±0.5	8.7±0.5	3.8±0.3	5.6±0.3	Receptacle	50 Pcs
			6.3 x 0.8	PVC	21.5±1.0	11.0±0.5	10.5±0.5	3.8±0.3	6.3±0.3	Blade	50 Pcs
				Nylon	21.5±1.0	7.36±0.5	11.3±0.5	4.8±0.3	7.3±0.3	Receptacle	40 Pcs
16-14 AWG	1.5-2.5 mm <sup>2</sup>	Blue	6.3 x 0.8	PVC	21.5±1.0	11.0±0.5	10.5±0.5	4.3±0.3	6.3±0.3	Blade	50 Pcs
				PVC	20.9±1.0	7.3±0.5	10.5±0.5	4.5±0.3	7.5±0.3	Receptacle	50 Pcs
				Nylon	22.0±1.0	7.3±0.5	11.0±0.5	4.8±0.3	7.5±0.3	Receptacle	35 Pcs