

LogiLink®

Mobile EV Charging Station

Safety Plug CEE 7/7 to Type 2 Plug
with Protection Bag, 5 m

Art. No.: EVL0100



Safely charge your electric cars on any 230 V household outlet with LogiLink Mobile EV Charging Station. Suitable for charging plug-in hybrid (PHEV) and battery electric vehicles (BEV) on the road and at home.

Features:


- » Portable charging solution with Safety plug CEE 7/7 to Type 2 plug
- » Fast charging with max. 3.7 kW/16 A
- » 5 selectable charging powers and is easy to operate
- » Clear control display providing information about the current charging process
- » CE & TUV certified
- » IP67 and multiple charging protections



Specifications:

Connector 1	Safety plug CEE 7/7
Connector 2	IEC 62196-2 Type 2 charging plug, female
Nominal Voltage	230 V~ 50 Hz
Selectable Current	6 A/8 A/10 A/13 A/16 A
Charging Mode	Mode 2
Connection	Single Phase
Protection Class	IP67 for the control box
Operating Temperature	-30–50°C
Operating Humidity	5–95% RH (non-condensing)
Cable Type	H07BZ5-F 3*2.5 mm ² +1*0.5 mm ² , PUR
Cable Length (Include Plug)	5 m
Dimensions	22 x 8.5 x 5.4 cm (control box)
Weight	Approx. 2.1 kg
Color	Black
Charging Protections	Overvoltage, undervoltage, overcurrent and over-temperature
Standard	IEC 62196-1, IEC 62196-2, EN 50620:2017/A1:2019, IEC 60332-1-2, IEC 61851, IEC 60811-404, IEC 60754-2, IEC 60068-2-5

Charger Display:

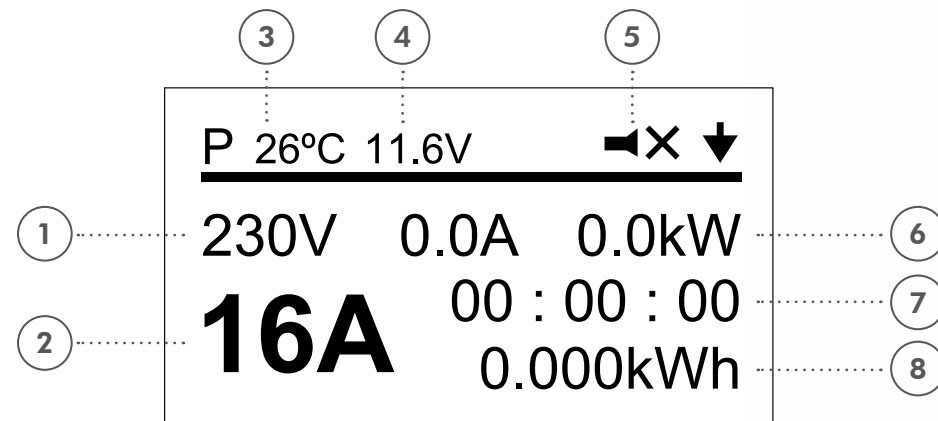

- | | |
|--------------------------------|----------------------------|
| 1 Input AC voltage | 5 Mode status |
| 2 Charging current | 6 Input power |
| 3 Charger's temperature | 7 Charging time |
| 4 Output voltage | 8 Charging capacity |



Available Connectors:

Art-No.	EVL0100FR	EVL0100UK	EVL0100SW	EVL0100DK	EVL0100IT
Plug Drawing					
Country	France	UK	Switzerland	Denmark	Italy
Cable	H07BZ5-F 3*2.5 mm ² , PUR	H07BZ5-F 3*2.5 mm ² , PUR	H07BZ5-F 3*2.5 mm ² , PUR	H07RN-F 3*1.5 mm ²	H07RN-F 3*1.5 mm ²

Package Contents:

- » 1 x Household Charging Cable
- » 1 x Protection Bag
- » 1 x User Manual

Package Information:

- » Packing Dimension: 360 x 360 x 90 mm
- » Packing Weight: kg
- » Carton Dimension: 380 x 380 x 380 mm
- » Carton Q'ty: 4 pcs
- » Carton Weight: kg



*The specifications and pictures are subject to change without prior notice.
*All trade names referenced are the registered trademarks of their respective owners.



EVL0100



4 052792 070682

Made in China