

DATASHEET

Item No.: 2986444


Type designation: CR2450 Common: CR2450

Chemical system: Lithium

Nominal voltage: 3.0 V

Average weight: 6.2 g

Dimensions: (mm)

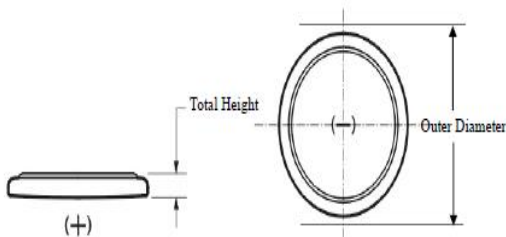

Designation	CR2450
Outer Diameter	24.2~24.5
Total Height	4.6~5.0

Capacity: 580 mAh (7.5K Ω , 24h/d, 20 \pm 2 $^{\circ}$ C, RH: 35%-75%, end voltage=2.0V)

Operating temperature: -18 $^{\circ}$ C~50 $^{\circ}$ C

Recommended storage temperature: 0~30 $^{\circ}$ C, 55 \pm 20%RH

Shelf lifetime: 5 year