



WXsmart Tweezers

- + Fast. Precise. Smart.
- + Extremely short heat-up time. (Micro 5 sec./ Ultra 10 sec.)
- + Excellent retraction times
- + Precise positioning ensured with unique parallel sliding block guide.
- + Fastest Tip Change
- + Compatible with: WXsmart control unit

WXMTS

Micro 2 x 40 W, 12 V
Order No. T0051320999



WXUTS

Ultra 2 x 75 W, 24 V
Order No. T0051321099



WXMTS Set

Smart Micro Soldering and Desoldering Set incl. WXMTS Tweezers 80 W, 24 V, RTWMS 030 K Tips (2 x 40 W) and WSR 210 Safety Rest (RTWMS/RTWPS Tip type series)
Order No. T0051321299




WXUTS Set

Smart Ultra Soldering and Desoldering Set incl. WXUTS Tweezers 150 W, 24 V, RTWUS 015 B Tips (2 x 75 W) and WSR 210 Safety Rest (RTWUS Tip type series)
Order No. T0051321399

RTWPS Smart Pico Tweezers Tips

- + High performance tips for the smallest components:
- + 0402 down to 01005
- + Short tip-to-grip distance
- + MIL-SPEC / IPC standard (potential free, MS versions)

CONICAL

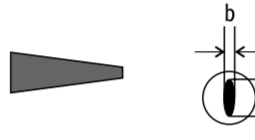


For use with



Model	MIL-SPEC VERSION AVAILABLE	Watt	a / b (mm) (inch.)	Order No.
RTWPS 001 C MS		2 x 40	∅ 0,1 ∅ 0.004	T0050115499
RTWPS 001 C X HM		2 x 40	∅ 0,1 ∅ 0.004	T0050115599

CHISEL BENT

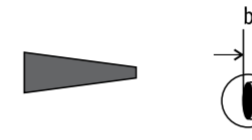


Model	MIL-SPEC VERSION AVAILABLE	Watt	a / b (mm) (inch.)	Order No.
RTWPS 002 S X		2 x 40	0,2 x 0,1 0.008 x 0.004	T0050115699
RTWPS 002 S X HM		2 x 40	0,2 x 0,1 0.008 x 0.004	T0050115799

RTWMS Smart Micro Tweezers Tips

- + High performance active tips for micro and standard
- + MIL-SPEC / IPC standard

CONICAL BENT

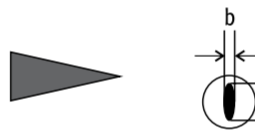

For use with



Model	MIL-SPEC VERSION AVAILABLE	Watt	a / b (mm) (inch.)	Order No.
RTWMS 001 C NW X		2 x 40	∅ 0,1 ∅ 0.004	T0050116699
RTWMS 004 C X		2 x 40	∅ 0,4 ∅ 0.016	T0050115899

CHISEL BENT



Modell	MIL-SPEC VERSION AVAILABLE	Watt	a / b (mm) (pouce)	Order No.
RTWMS 007 S X		2 x 40	0,7 x 0,4 0.027 x 0.016	T0050115999
RTWMS 013 S		2 x 40	1,3 x 0,4 0.051 x 0.016	T0050116299
RTWMS 008 S		2 x 40	0,8 x 0,4 0.031 x 0.016	T0050116799

BLADE



Model	MIL-SPEC VERSION AVAILABLE	Watt	a / b (mm) (inch.)	Order No.
RTWMS 030 K		2 x 40	3,0 x 1,0 0.118 x 0.039	T0050116099
RTWMS 060 K		2 x 40	6,0 x 1,0 0.236 x 0.039	T0050116199
RTWMS 100 K		2 x 40	10,0 x 1,0 0.394 x 0.039	T0050116499
RTWMS 030 K S		2 x 40	3,0 x 1,0 0.118 x 0.039	T0050116399
RTWMS 060 K		2 x 40	6,0 x 1,0 0.236 x 0.039	T0050116599

RTWUS Smart Ultra Tweezers Tips

- + Designed for heavy duty applications and large components
- + Thermal Core Technology for optimized heat transfer
- + MIL-SPEC / IPC standard

BEVEL CUT



For use with



Model	MIL-SPEC VERSION AVAILABLE	Watt	a / b (mm) (inch.)	Order No.
RTWUS 015 B		2 x 75	1,5 0,059	T0050116899
RTWUS 026 B		2 x 75	2,6 0,102	T0050116999

Micro and standard components

Active Tip



Heat up time

°C
-350
-300
-200
-100
-0

RTWPS 3 sec*
RTWMS 5 sec*
RTWUS 7 sec*

Component size



*from 50°C to 350°C / 120°F to 620°F



BLADE



Model	MIL-SPEC VERSION AVAILABLE	Watt	a / b (mm) (inch.)	Order No.
RTWUS 060 K		2 x 75	6 0,236	T0050117099
RTWUS 100 K		2 x 75	10 0,393	T0050117199
RTWUS 200 K		2 x 75	20 0,787	T0050117299
RTWUS 150 K		2 x 75	15 0,59	T0050117399

Weller

weller-tools.com/wxsmart

TWEEZERS
WXsmart

Movie



Discover more

