


LogiLink®

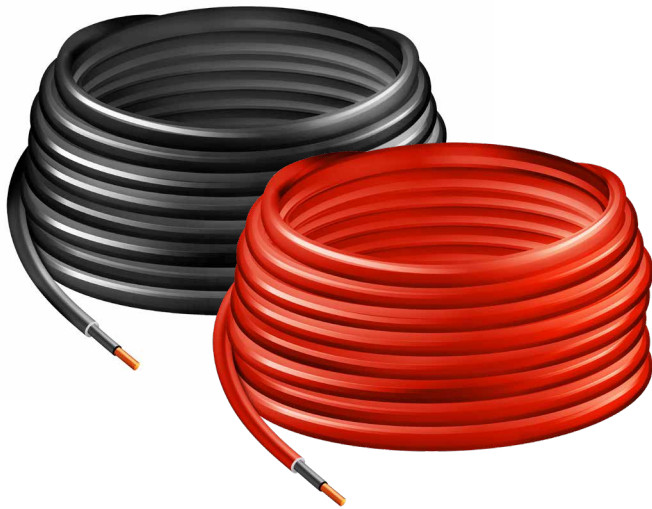

Solar Installation Cable



25 m

Art. No.: PHC0200
PHC0201

LogiLink Solar Installation Cable is made of tin-plated copper, ensuring good electrical conductivity and insulation. Sheath made with high-quality XLPO, flame retardant, low toxicity, good resistance to aging, UV rays and works in extreme temperatures.

Features:

- » Conforms to industry standards: EN 50618:2014, IEC 60332-1-2
- » Works with PHC0300 (Solar MC4 connectors)
- » Cable length: 25 m

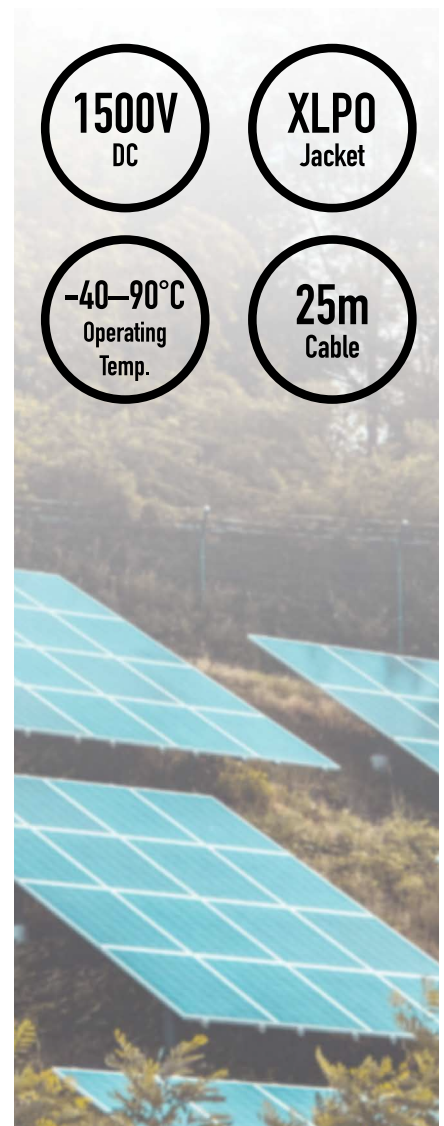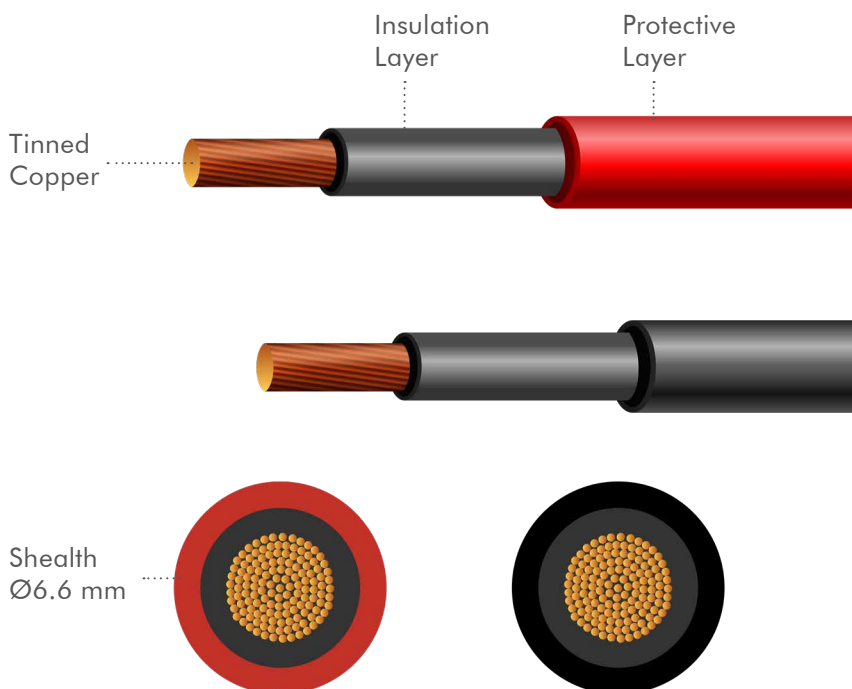

| Art-No. | Color | EAN Code |
|---------|-------|---------------|
| PHC0200 | Black | 4052792070934 |
| PHC0201 | Red | 4052792070941 |



*The specifications and pictures are subject to change without prior notice.
*All trade names referenced are the registered trademarks of their respective owners.

Made in China

Specifications:

| | |
|-----------------------------|----------------------|
| Standard | EN 50618 H1Z2Z2 K |
| Cross-Section | 6 mm ² |
| Conductor Structure | 84 x Ø0.285±0.005 mm |
| Sheath | Ø6.6±0.1 mm |
| Jacket | XLPO |
| Rated Voltage | 1500 V |
| Rated Current | 60 A |
| Operating Temperature Range | -40–90°C |
| Max. DC Resistance at 20°C | 3.39 Ω/km |
| Cable Length | 25 m |

Package Content:

» 1 x Solar Installation Cable

Package Information:

| Art-No. | Packing Dimension | Packing Weight | Carton Dimension | Carton Q'ty | Carton Weight |
|---------|-------------------|----------------|------------------|-------------|---------------|
| PHC0200 | 230 x 230 x 60 mm | 2.1 kg | mm | 8 pcs | 17.5 kg |
| PHC0201 | 230 x 230 x 60 mm | 2.1 kg | mm | 8 pcs | 17.5 kg |



*The specifications and pictures are subject to change without prior notice.
*All trade names referenced are the registered trademarks of their respective owners.

Made in China