

LogiLink®

4K DisplayPort™ Splitter 1x3 Ports

4K/60 Hz, 1 DP to 3 HDMI™


Art. No.: CV0146



The DisplayPort 1.4 Splitter from LogiLink allows one DisplayPort enabled computer the ability to be displayed on three HDMI monitors simultaneously. You can extend your desktop or mirror the screen with 4K Ultra HD resolution.

Features:

- » Connects one DisplayPort source to three HDMI displays at the same time
- » Compliant with DisplayPort 1.4
- » Resolution up to UHD 4K@60 Hz (30 Hz for connection of three monitors)
- » Bandwidth up to 18 Gbps (6 Gbps per channel)
- » Supports output pixel format RGB/YCbCr4:4:4/YCbCr4:2:2/YCbCr4:2:0
- » Supports MST (Multi Stream Transport) and SST (Single Stream Transport)
- » Supports HDCP 2.2 & 1.4, DPCP, HDR, DDC, DSC, HFR, TMDS and 3D formats
- » Plug & play for easy to use
- » Powered by USB

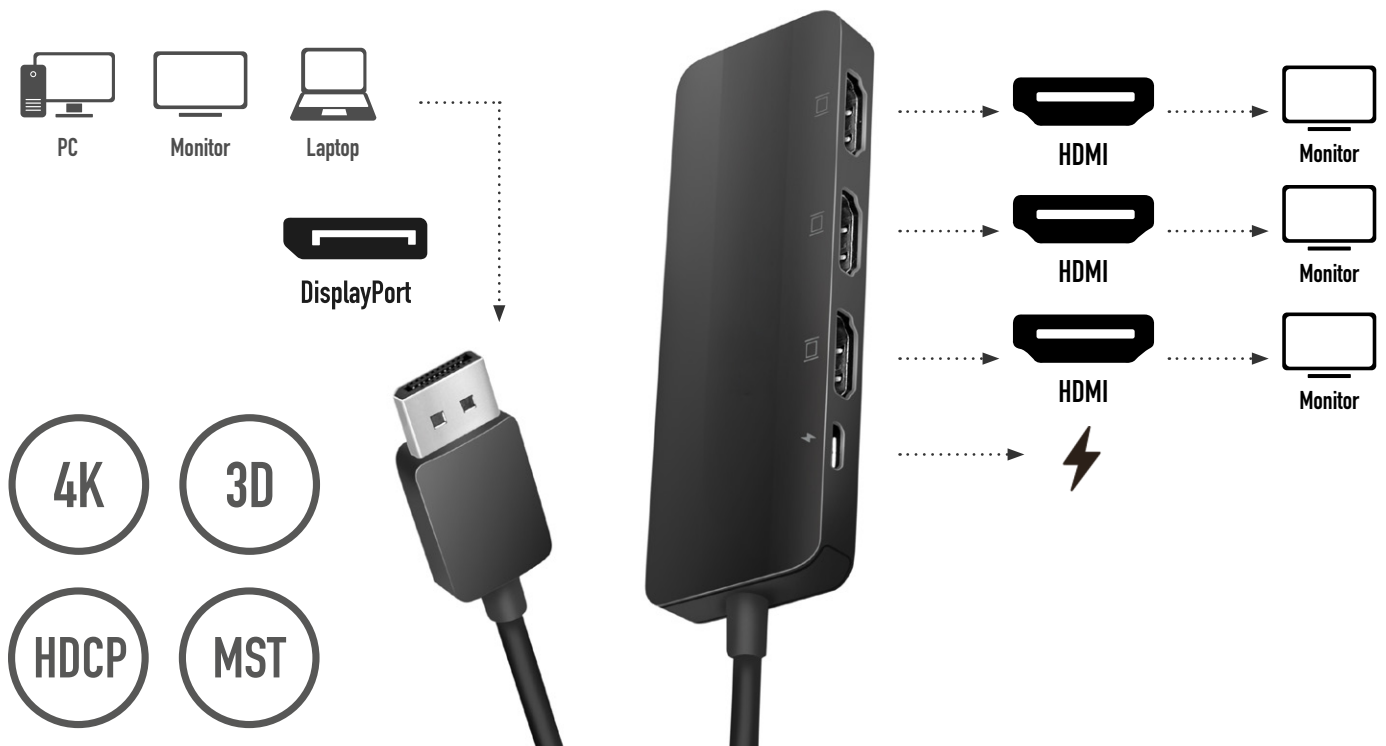

CV0146



4 052792 067569

Made in China



*The specifications and pictures are subject to change without prior notice.
*All trade names referenced are the registered trademarks of their respective owners.

Specifications:

Input Ports	1x DisplayPort male, 1x Micro USB female
Output Ports	3x HDMI-A female
DisplayPort Version	1.4
HDCP Version	2.2 & 1.4
DPCP Version	1.0
Output Resolution	Max. 4K/60 Hz *1x 4K/60 Hz + 2x 4K/30 Hz for connection of three monitors
Video Bandwidth	6 Gbps per channel (3 channels total 18 Gbps)
Transmission Modes	RBR, HBR, HBR2, HBR3
EDID Management	Pass-through
Multi-Stream Transport (MST)	Yes
TMDS	Yes
3D Support	Yes
Hot Pluggable	Yes
Audio	LPCM 7.1, Dolby TrueHD, DTS-HD
Display Mode	Main/extended/mirror
Power By	Micro USB
Power Consumption	3 W max.
Housing Material	ABS
Color	Black
Operating Temperature	0–45°C
Operating Humidity	10–85% RH (no condensation)
Dimensions	32.9 x 3.6 x 1.15 cm (cable included)
Weight	60.5 g
Cable Length	17 cm

Package Contents:

- » 1 x DisplayPort Splitter
- » 1 x User Manual

Package Information:

- » Packing Dimension: mm
- » Packing Weight: kg
- » Carton Dimension: mm
- » Carton Q'ty: pcs
- » Carton Weight: kg



*The specifications and pictures are subject to change without prior notice.
*All trade names referenced are the registered trademarks of their respective owners.



CV0146



Made in China