



# LogiLink®

## USB 3.2 Gen 1 USB-C™ Docking Station

7-Port, 100 W USB-PD

Art. No.: UA0410



## Expand Your USB-C Devices' Capabilities


This USB-C Docking Station is a portable and lightweight 7-in-1 expansion dock; simply connect projectors, 4K monitors, USB flash drives and gigabit ethernet on your USB-C laptop/tablet. The extra USB-C PD port keeps your laptop charging while providing power to each external device. Great for increasing your work efficiency and making life easier.



## 7-in-1 Expansion

Instantly expand your USB-C laptop/tablet with:

- 1x RJ45 Gigabit Ethernet port
- 1x HDMI output port
- 1x VGA output port
- 3x USB 3.0 ports
- 1x USB-C PD 100 W

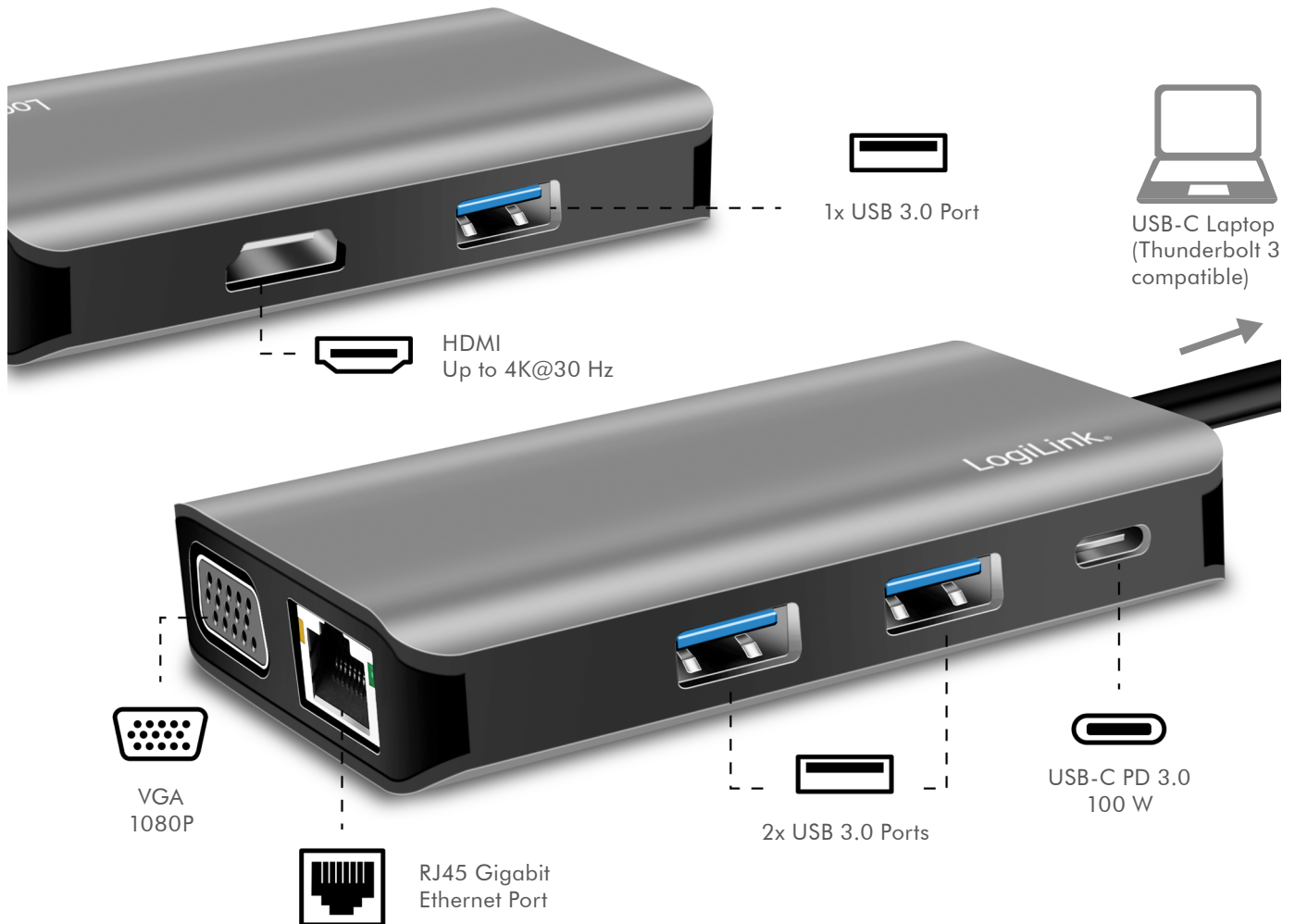

## Convenient USB-C Charging

Power supply via the 100 W USB-C Power Delivery port for keeps your laptop/tablet fully charged while you're using all the other devices on the docking.








### Fast Data Transfer

Connect your laptop/tablet via the USB-C port (Thunderbolt 3 compatible) to give you extra ports to connect your peripherals. Quick data transfer speeds up to 5 Gbps.

### Crystal Clear & Simultaneous Video Output

Extend up to two monitors through one HDMI port and one VGA port at the same time. Easily stream videos to a HDTV, monitor or projector; enjoy your crisp and colorful pictures.

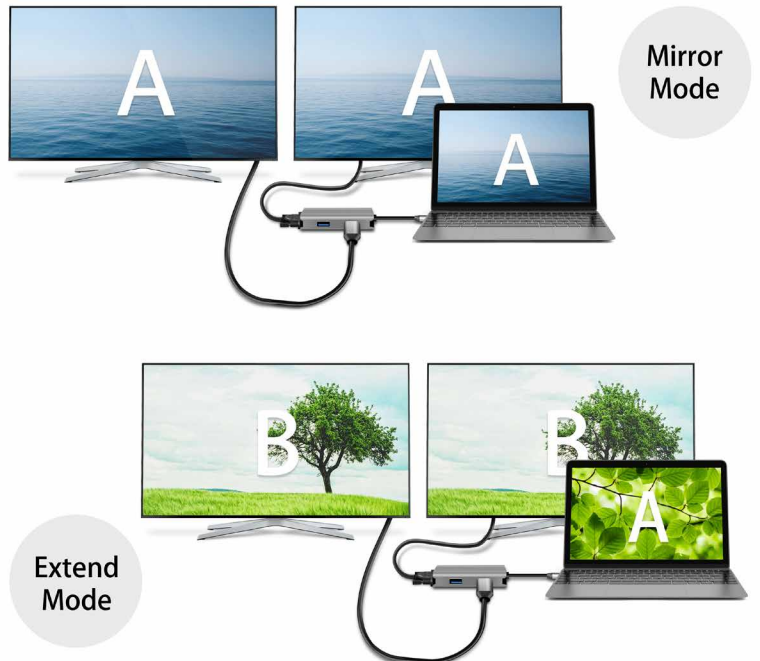

### Steady Internet Performance

RJ45 Gigabit Ethernet Network Port provides stable and fast network transmission (10M/100M/1000 Mbps). Allows you to transfer large files or make backups to a server and network storage device.

## Specification:

Input	USB-C plug, USB-C PD charging port
Output	3x USB-A female, 1x VGA female, 1x HDMI female, 1x RJ45 female
HDMI Standard	HDMI 1.4
USB Standard	USB 3.2 Gen 1
Data Transfer Rate	Up to 5 Gbps
Compatible Thunderbolt 3	Yes
Max. USB-C PD Output	5 V/3 A (15 W), 9 V/3 A (27 W), 12 V/3 A (36 W), 15 V/3 A (45 W), 20 V/5 A (100 W)
DisplayPort Alternate Mode	Support
HDCP Version	1.4
Output Resolution	HDMI: up to 4K@30 Hz VGA: up to 1920x1080@60 Hz
Ethernet Standard	IEEE802.3, IEEE802.3u, IEEE802.3ab, IEEE802.az
Ethernet Speed	10/100/1000 Mbps
Power By	USB bus powered
Max. Power Consumption	5 W
Operating Temperature	0–45°C
Operating Humidity	25–60% RH (No condensation)
Works With	Connected devices must support USB-C DP Alternate Mode
Compatibility	Windows, Mac OS, Android, Chrome OS and iPad OS
Housing Material	Aluminum
Color	Space grey
Attached Cable Length	20 cm
Dimensions	29 x 5.55 x 1.7 cm (cable included)
Weight	83 g

## Package Contents:

- » 1x USB-C Docking Station
- » 1x User Manual

## Package Information:

- » Packing Dimension: 75 x 25 x 138 mm
- » Packing Weight: 0.106 kg
- » Carton Dimension: 395 x 275 x 155 mm
- » Carton Q'ty: 50 pcs
- » Carton Weight: 5.6 kg

! Proper use of the PD function can only be guaranteed in combination with certified USB cables with E-Mark chipset.



UA0410



4 052792 070118

Made in China



\*The specifications and pictures are subject to change without prior notice.  
\*All trade names referenced are the registered trademarks of their respective owners.