


Insulated Cable Ferrules, 2110pcs DIN Color Coding (0.14-16.0mm²)

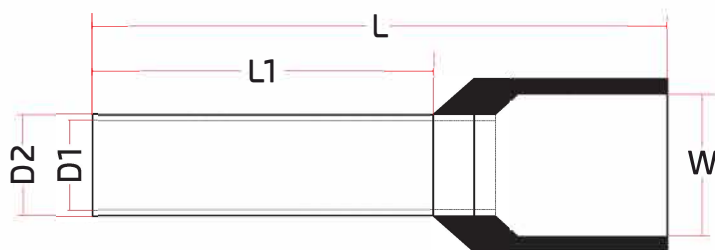

Technical Data:

Color code type: DIN
 Terminal material: Copper
 Terminal coating: Tin
 Insulation material:
 0.14mm² - 0.34mm²: PA
 0.50mm² - 16.0mm²: PVC
 Max. voltage rating: 600V
 Max. temperature rating:
 0.14mm² - 0.34mm²: 105°C max.
 0.50mm² - 16.0mm²: 75°C max.

Wire Guide	Cross Section	Dimension (mm)					Color	Quantity
		L	L1	øD1	øD2	W		
28 AWG	0.14 mm ²	10.3 ±1.0	6.0 ±0.6	0.7 ±0.2	1.1 ±0.2	1.7 ±0.3	Grey	200 Pcs
26 AWG	0.25 mm ²	10.5 ±1.0	6.0 ±0.6	0.7 ±0.2	1.1 ±0.2	1.9 ±0.3	Light Blue	250 Pcs
24 AWG	0.34 mm ²	10.5 ±1.0	6.0 ±0.6	0.8 ±0.2	1.1 ±0.2	1.9 ±0.3	Turquoise	250 Pcs
22 AWG	0.50 mm ²	14.2 ±1.0	8.0 ±0.6	0.9 ±0.2	1.3 ±0.2	2.5 ±0.3	White	250 Pcs
20 AWG	0.75 mm ²	15.1 ±1.0	8.0 ±0.6	1.2 ±0.2	1.5 ±0.2	2.8 ±0.3	Grey	250 Pcs
18 AWG	1.00 mm ²	14.7 ±1.0	8.0 ±0.6	1.4 ±0.2	1.8 ±0.2	2.9 ±0.3	Red	250 Pcs
16 AWG	1.50 mm ²	15.4 ±1.0	8.0 ±0.6	1.6 ±0.2	2.0 ±0.2	3.4 ±0.3	Black	250 Pcs
14 AWG	2.50 mm ²	15.6 ±1.0	8.0 ±0.6	2.2 ±0.2	2.6 ±0.2	4.1 ±0.3	Blue	200 Pcs
12 AWG	4.00 mm ²	17.2 ±1.0	9.0 ±0.6	2.8 ±0.2	3.2 ±0.2	4.8 ±0.3	Grey	100 Pcs
10 AWG	6.00 mm ²	20.5 ±1.0	12.0 ±0.6	3.5 ±0.2	3.9 ±0.2	6.2 ±0.3	Yellow	50 Pcs
7 AWG	10.00 mm ²	27.0 ±1.0	18.0 ±0.6	4.5 ±0.2	4.9 ±0.2	7.5 ±0.3	Red	35 Pcs
5 AWG	16.00 mm ²	22.5 ±1.0	12.0 ±0.6	5.8 ±0.2	6.2 ±0.2	8.7 ±0.3	Blue	25 Pcs