


# Insulated Cable Ferrules, 2065pcs Standard and Twin assortment DIN Color Coding (0.5-4.0mm<sup>2</sup>)

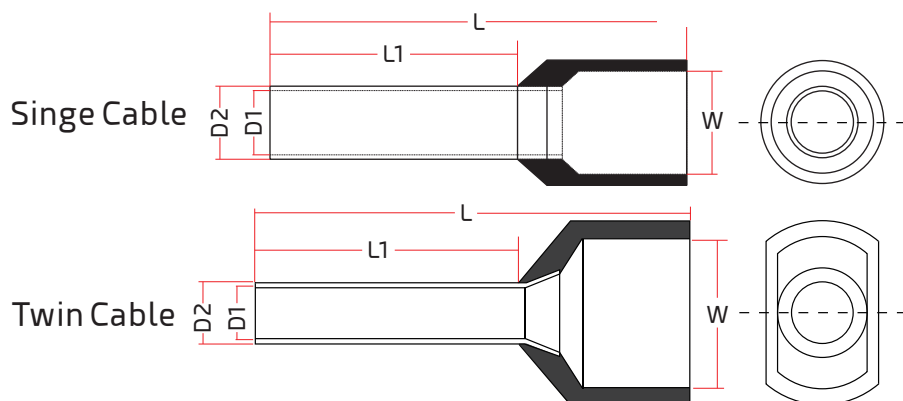

## Technical Data:

Color code type: DIN  
 Terminal material: Copper  
 Terminal coating: Tin  
 Insulation material: PVC  
 Max. voltage rating: 600V  
 Max. temperature rating: 75°C

Wire Guide	Cross Section	Dimension (mm)					Color	Quantity
		L	L1	øD1	øD2	W		
22 AWG	0.50 mm <sup>2</sup>	14.2 ±1.0	8.0 ±0.6	0.9 ±0.1	1.3 ±0.1	2.5 ±0.3	White	250 Pcs
20 AWG	0.75 mm <sup>2</sup>	15.1 ±1.0	8.0 ±0.6	1.2 ±0.1	1.5 ±0.2	2.8 ±0.3	Grey	250 Pcs
18 AWG	1.00 mm <sup>2</sup>	14.7 ±1.0	8.0 ±0.3	1.4 ±0.1	1.8 ±0.2	2.9 ±0.2	Red	250 Pcs
16 AWG	1.50 mm <sup>2</sup>	15.4 ±1.0	8.0 ±0.3	1.6 ±0.1	2.0 ±0.1	3.4 ±0.2	Black	250 Pcs
14 AWG	2.50 mm <sup>2</sup>	15.6 ±1.0	8.0 ±0.3	2.2 ±0.1	2.6 ±0.1	4.1 ±0.3	Blue	200 Pcs
12 AWG	4.00 mm <sup>2</sup>	17.2 ±1.0	8.0 ±0.3	2.8 ±0.3	3.2 ±0.1	4.8 ±0.6	Grey	100 Pcs
2x 22 AWG	2 x 0.50 mm <sup>2</sup>	14.5 ±1.0	8.0 ±0.6	1.5 ±0.2	1.8 ±0.2	5.0 ±0.3	White	200 Pcs
2 x 20 AWG	2 x 0.75 mm <sup>2</sup>	14.7 ±1.0	8.0 ±0.6	1.8 ±0.2	2.1 ±0.2	5.5 ±0.3	Grey	200 Pcs
2 x 18 AWG	2 x 1.00 mm <sup>2</sup>	15.5 ±1.0	8.0 ±0.6	2.0 ±0.2	2.3 ±0.2	5.5 ±0.3	Red	150 Pcs
2 x 16 AWG	2 x 1.50 mm <sup>2</sup>	15.5 ±1.0	8.0 ±0.6	2.3 ±0.2	2.6 ±0.2	6.4 ±0.3	Black	100 Pcs
2 x 14 AWG	2 x 2.50 mm <sup>2</sup>	19.3 ±1.0	10.0 ±0.6	2.9 ±0.2	3.3 ±0.2	8.0 ±0.3	Blue	75 Pcs
2 x 12 AWG	2 x 4.00 mm <sup>2</sup>	23.1 ±1.0	12.0 ±0.6	3.5 ±0.2	4.2 ±0.2	8.8 ±0.3	Grey	40 Pcs