


Insulated Cable Ferrules 0.5mm² x 8 mm, White 100Pcs

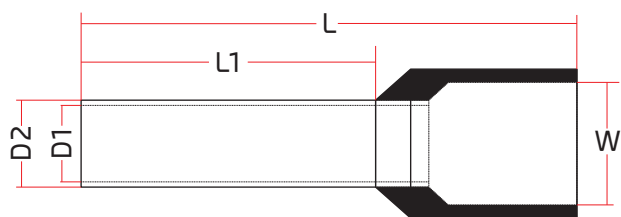

Technical Data:

Color type: DIN
 Terminal material: Copper
 Terminal coating: Tin
 Insulation material: PVC
 Max. voltage rating: 600V
 Max. temperature rating: 75°C

Wire Guide	Cross Section	Dimension (mm)					Color	Quantity
		L	L1	øD1	øD2	W		
22 AWG	0.50 mm ²	14.2 ±1.0	8.0 ±0.6	0.9 ±0.1	1.3 ±0.1	2.5 ±0.3	White	100 pcs